


# E11737



## Connecting cable with socket

ADOGK120MSS0010H12

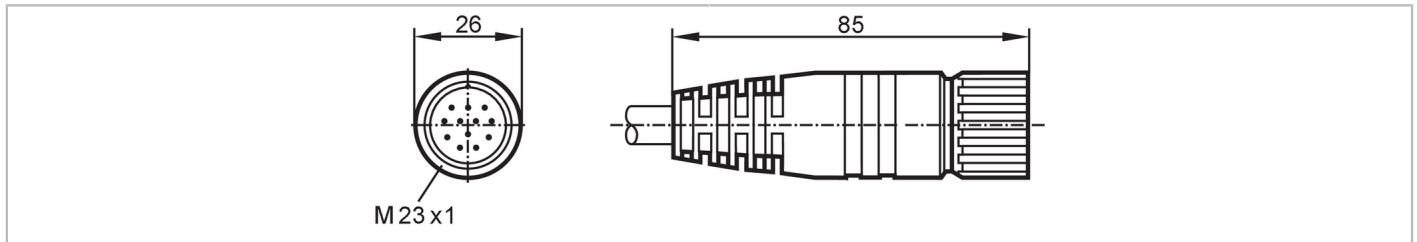

### Application

Special feature	Halogen-free
Application	Industrial applications / factory automation

### Electrical data

Operating voltage	[V]	< 63 AC/DC
-------------------	-----	------------

### Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

### Mechanical data

Weight	[g]	1388.5
Dimensions	[mm]	26 x 26 x 85
Moulded-body material		PUR
Material nut		brass, nickel-plated
Tightening torque	[Nm]	2

### Remarks


Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 9.3 mm; 8 x 0.5 mm<sup>2</sup> (63 x Ø 0.1 mm) + 3 x 1.0 mm<sup>2</sup> (127 x Ø 0.1 mm)

### Electrical connection - socket

Connector: 1 x M23, straight; Contacts: 12; Moulded body: PUR, black; Locking: brass, nickel-plated

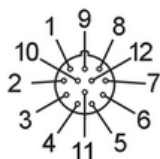


# E11737



## Connecting cable with socket

ADOGK120MSS0010H12

### Connection

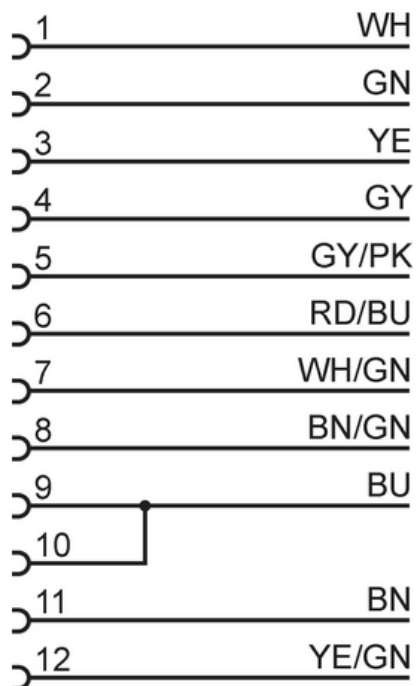

	Core colours :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow