


E11841




Wirable socket

SDOGH040PLSFKSK

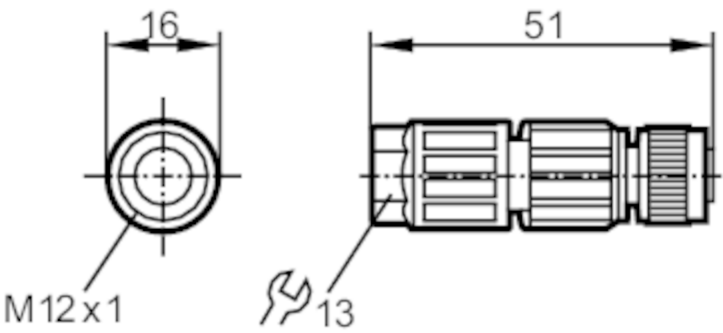

Electrical data		
Operating voltage	[V]	< 45 AC / < 70 DC
Operating conditions		
Ambient temperature	[°C]	-25...60
Protection		IP 67
Mechanical data		
Weight	[g]	12.1
Dimensions	[mm]	16 x 16 x 51
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		PA 6.6
Remarks		
Pack quantity		1 pcs.
Electrical connection		
insulation displacement technology: 0.14...0.34 mm²; Cable sheath: Ø 3.5...6 mm		
Electrical connection - socket		

 Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: PA 6.6



E11841

Wirable socket

SDOGH040PLSFKSK



Connection

