

E11865




Wirable socket

SDOAH050VASFKPG

Article no longer available - archive entry

Alternative articles: EVF570

When selecting an alternative article and accessories please note that technical data may differ!

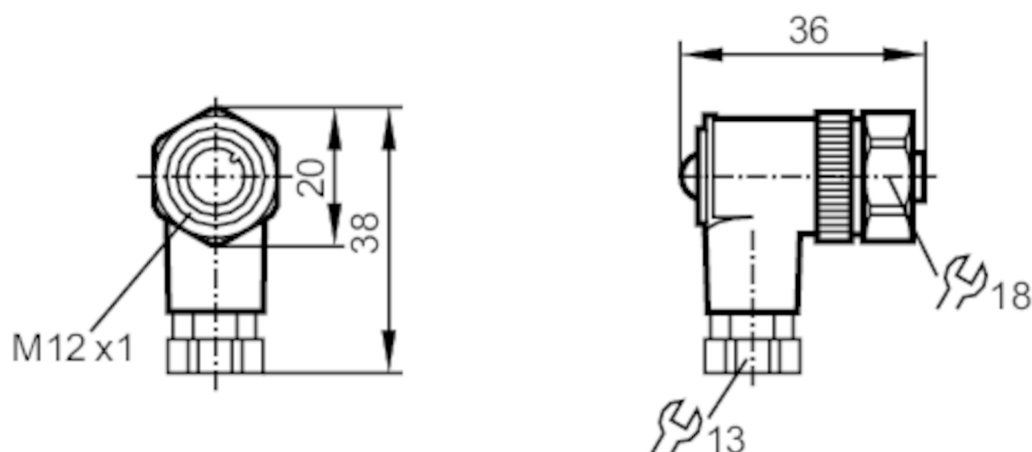

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	27.5
Materials		PA
Moulded-body material		PA
Material nut		stainless steel

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11865



Wirable socket

SDOAH050VASFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: stainless steel; Contacts: gold-plated



Connection

