


E11898



Ethernet connection cable

VSTGN040ZDS0002L04STGP040--S

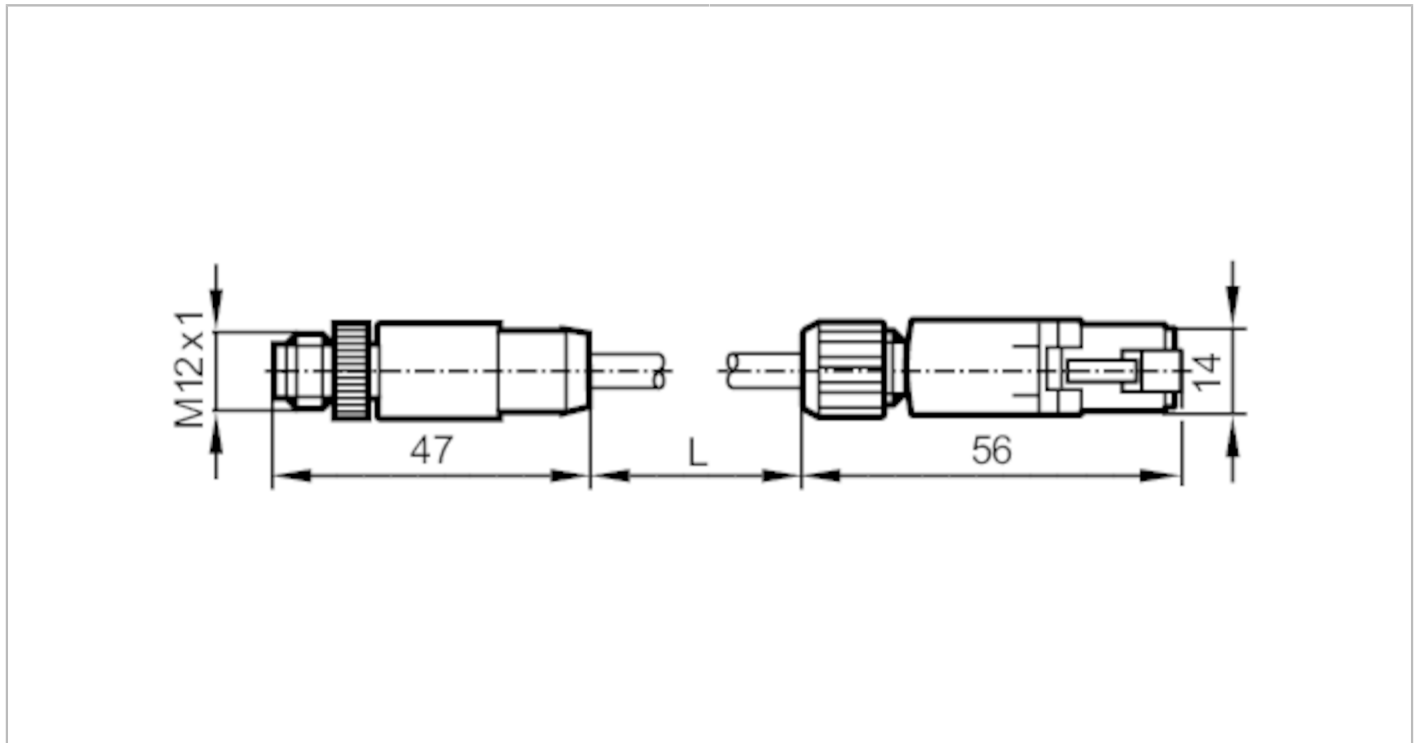

| Application | |
|--------------------------|--------------------------------------|
| Design | Ethernet cable, D-coded |
| Application | cross-over patch cable; patch cable |
| Operating conditions | |
| Ambient temperature [°C] | -25...70 |
| Protection | IP 67; IP 42; (M12 plug / RJ45 plug) |
| Mechanical data | |
| Weight [g] | 163.5 |
| Materials | PUR / PC |
| Moulded-body material | PUR / PC |
| Material nut | diecast zinc, nickel-plated |
| Remarks | |
| Pack quantity | 1 pcs. |

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E11898




Ethernet connection cable

VSTGN040ZDS0002L04STGP040--S

Electrical connection

Cable: 2 m, PVC, green, Ø 6.2 mm; 4 x 0.38 mm²

Connection

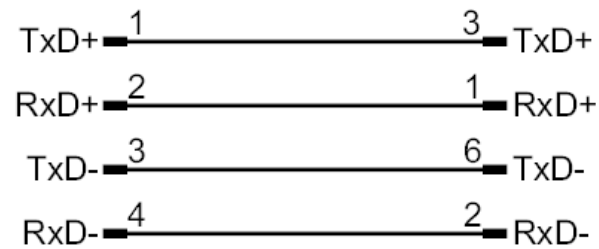

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

