


E11006



Connection cable

VSTGH050MSS00,6I03VDAA041--S

Article no longer available - archive entry

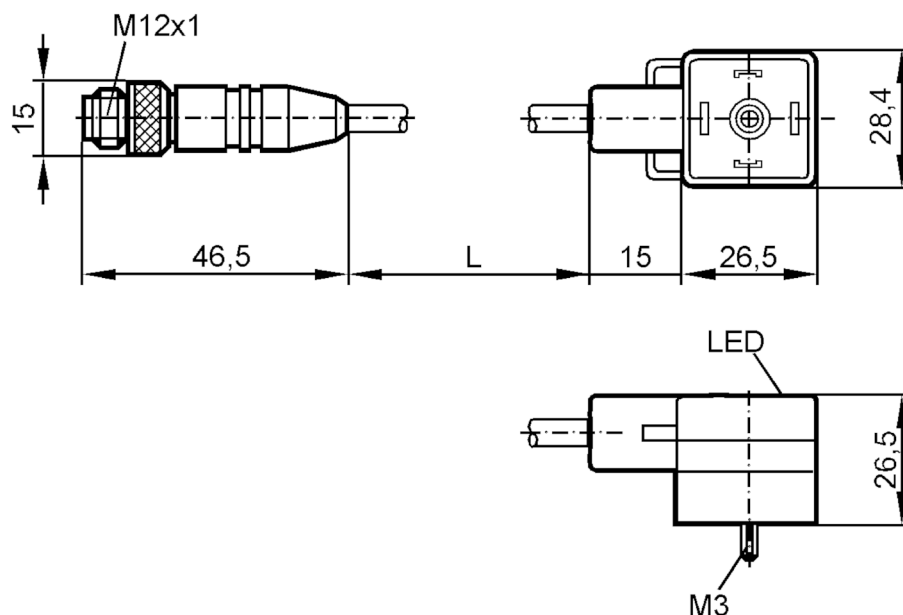

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Overvoltage protection yes; (VDR)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 46.5

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Accessories

Items supplied screw

panel for labelling

Remarks

Pack quantity 1 pcs.



Connection cable

VSTGH050MSS00,6I03VDAA041--S

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.6 m, PUR, Halogen-free; cross-linked; 3 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

