


E11009



Connection cable

VSTGH050MSS00,6I03VDAB031--S

Article no longer available - archive entry

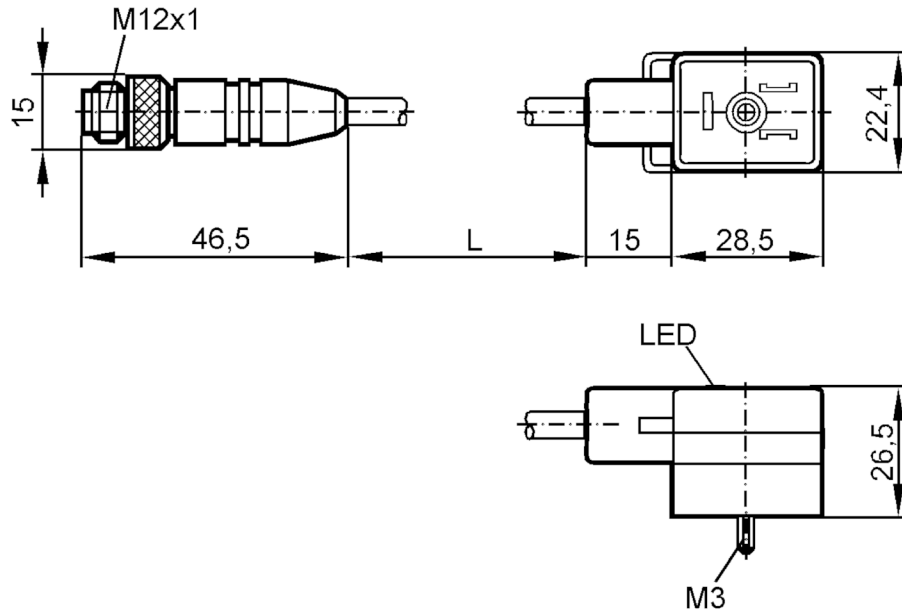

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 46.5

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

 
Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated

E11009



Connection cable


VSTGH050MSS00,6I03VDAB031--S



Electrical connection

Cable: 0.6 m, PUR, Halogen-free; cross-linked; 3 x 0.5 mm²

Connection

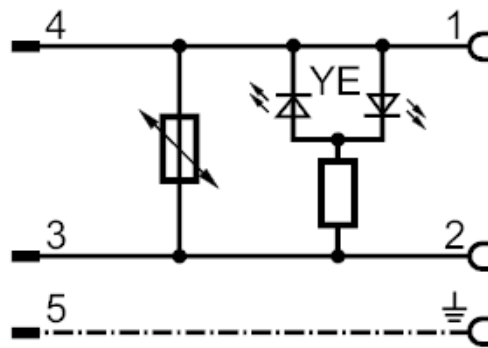

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

