


Connecting cable with socket

ADOGF030VAS0010E03

Article no longer available - archive entry

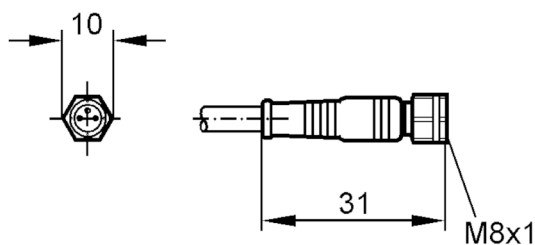

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67; (if screwed on)

Mechanical data

Dimensions	[mm]	10 x 10 x 31
Materials		TPU
Moulded-body material		TPU
Material nut		stainless steel (1.4305 / 303)

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: stainless steel (1.4305 / 303)



E11096



Connecting cable with socket

ADOGF030VAS0010E03

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue