




Connecting cable with socket

ADOGB050PLS0005E05

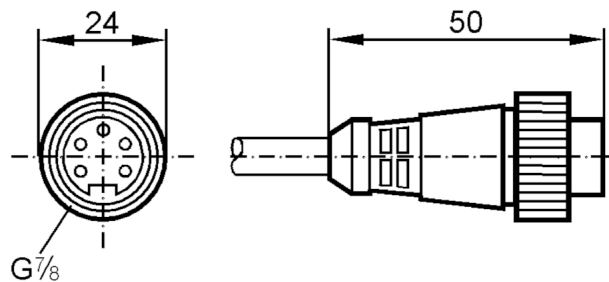

Electrical data

Operating voltage	[V]	< 250 AC
Max. current load total	[A]	5

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 68

Mechanical data

Weight	[g]	498.2
Dimensions	[mm]	24 x 24 x 50
Materials		TPU
Moulded-body material		TPU
Material nut		TPU

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PVC; 5 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU; Locking: TPU




E11246



Connecting cable with socket

ADOGB050PLS0005E05

Connection

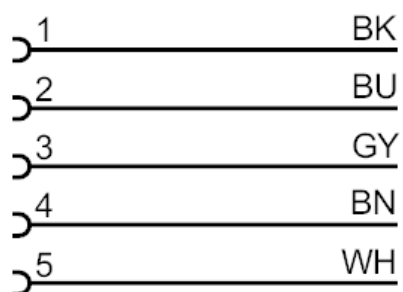

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white