


# E12408



## Adapter socket

EDOGH050MSS00,5E05 (M16)

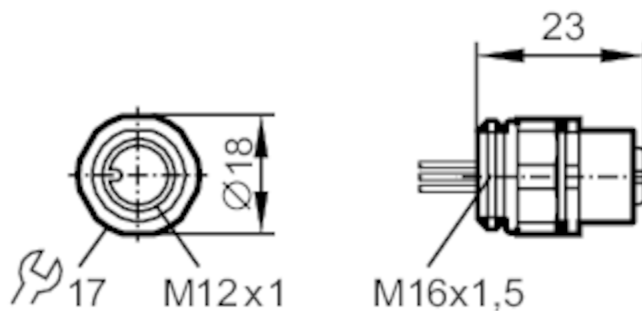

### Electrical data

|                   |     |             |
|-------------------|-----|-------------|
| Operating voltage | [V] | < 125 AC/DC |
|-------------------|-----|-------------|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 68    |

### Mechanical data

|                       |     |                             |
|-----------------------|-----|-----------------------------|
| Weight                | [g] | 23.6                        |
| Mounting thread       |     | M16                         |
| Materials             |     | diecast zinc nickel-plated  |
| Moulded-body material |     | diecast zinc, nickel-plated |

### Accessories

|                |  |                    |
|----------------|--|--------------------|
| Items supplied |  | nut: 1 x M16 x 1,5 |
|----------------|--|--------------------|

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12408



## Adapter socket


EDOGH050MSS00,5E05 (M16)

### Electrical connection

Cable: 0.5 m, PVC; 5 x 0.25 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc, nickel-plated

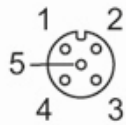

### Connection

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |
| 5 | GY |

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| GY = | grey           |
| WH = | white          |