


E12422



Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

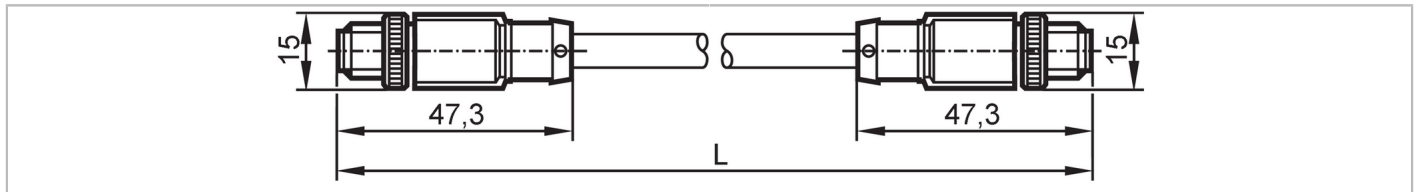

Application	
Special feature	Gold-plated contacts; Screened cable
Design	Ethernet cable, D-coded
Application	Industrial applications / factory automation
Electrical data	
Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-20...90
Protection	IP 67
Mechanical data	
Weight [g]	66.1
Dimensions [mm]	15 x 15 x 47.3
Materials	TPU
Moulded-body material	TPU
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Shielded connection cable: screen connected



E12422




Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

Electrical connection

Cable: 0.5 m, PVC, green, shielded; 4 x 0.34 mm²

Connection

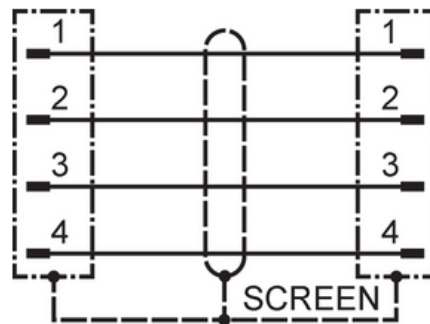

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Shielded connection cable: screen connected

