


E12491



Ethernet connection cable

VSTGN040ZDS0005L04STGP040--S

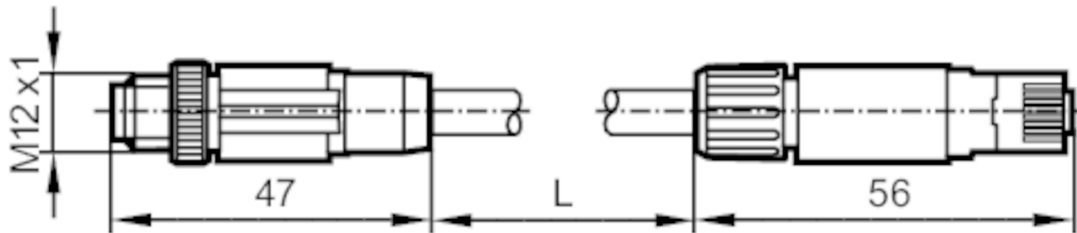

Application

Special feature	Screened cable
Design	Ethernet cable, D-coded
Application	cross-over patch cable; patch cable

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 20; (M12 plug / RJ45 plug)

Mechanical data

Weight	[g]	367.2
Materials		TPU / PA
Moulded-body material		PA / TPU
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12491




Ethernet connection cable

VSTGN040ZDS0005L04STGP040--S

Electrical connection

Cable: 5 m, PVC, green, Ø 6.5 mm, shielded; 2 x 2 x 0.38 mm²

Connection

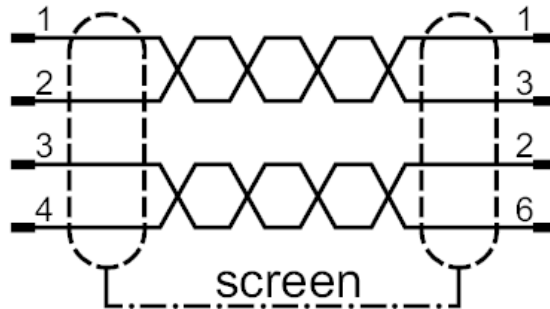

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: TPU

