


# E12491



## Ethernet connection cable

VSTGN040ZDS0005L04STGP040--S

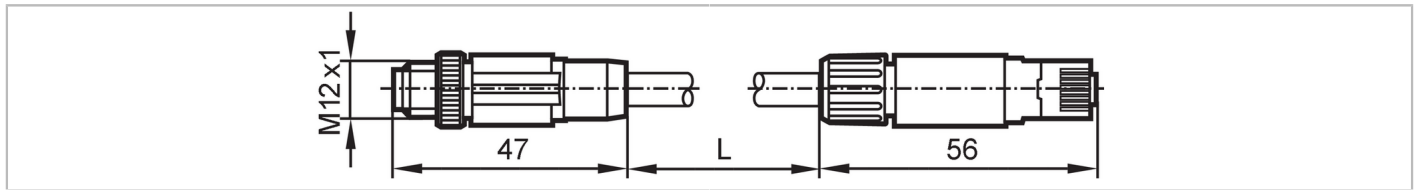

Application	
Special feature	Screened cable
Design	Ethernet cable, D-coded
Application	cross-over patch cable; patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 20; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	367.2
Materials	TPU / PA
Moulded-body material	PA / TPU
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

### Electrical connection - plug M12


Connector: 1 x M12, straight; coding: D; Contacts: 4; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 5 m, PVC, green, Ø 6.5 mm, shielded; 2 x 2 x 0.38 mm<sup>2</sup>

### Connection

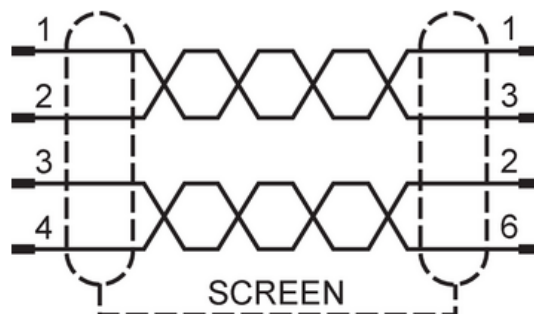

# E12491



## Ethernet connection cable

VSTGN040ZDS0005L04STGP040--S

### Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Contacts: 8; Moulded body: TPU

