


E12493



Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

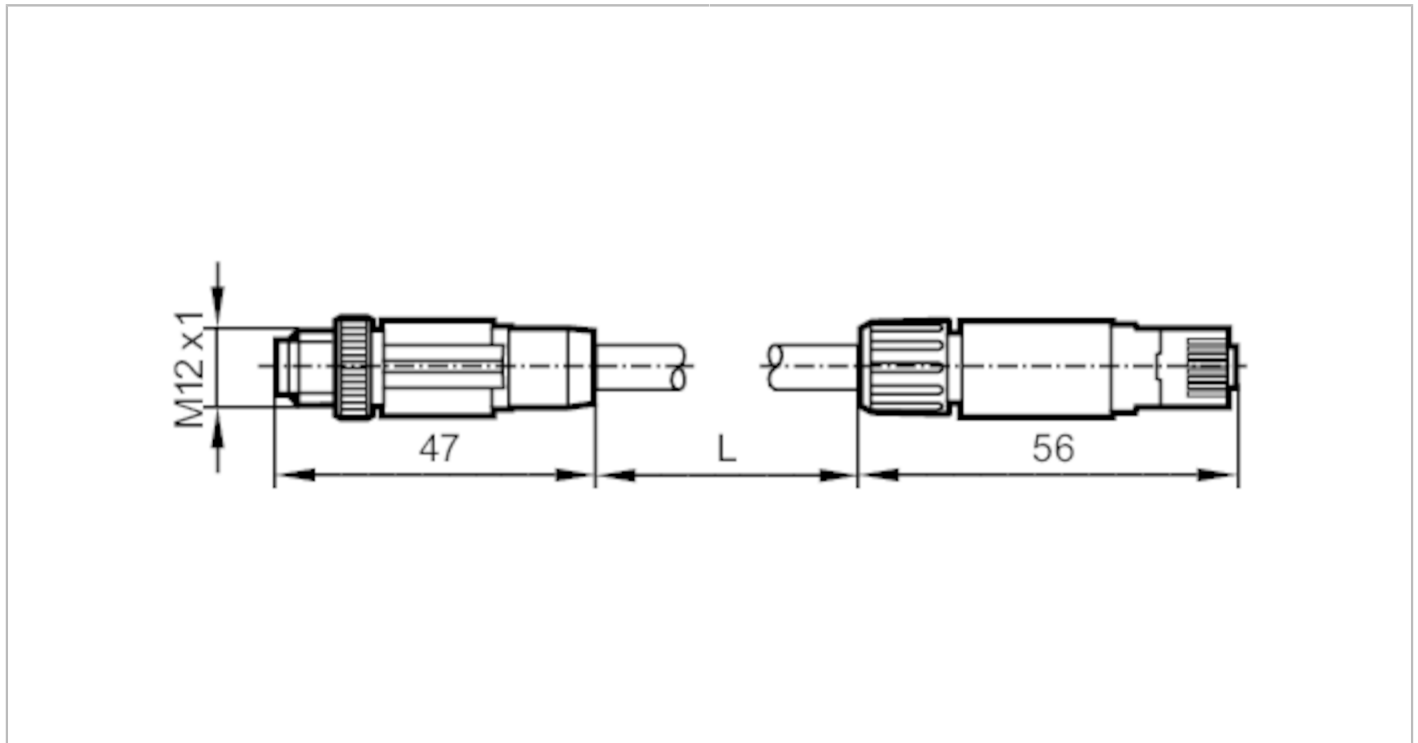

Application	
Special feature	Screened cable
Design	Ethernet cable, D-coded
Application	cross-over patch cable; patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 20; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	1364.5
Materials	TPU / PA
Moulded-body material	PA / TPU
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12493




Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

Electrical connection

Cable: 20 m, PVC, green, \varnothing 6.5 mm, shielded; 2 x 2 x 0.38 mm²

Connection

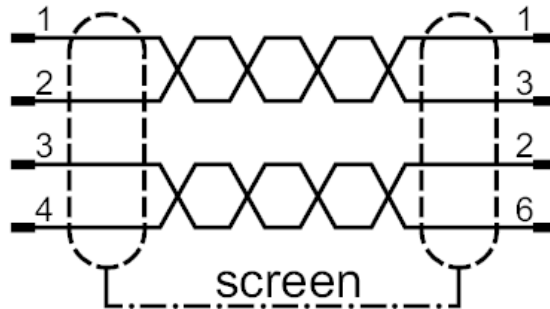

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: TPU

