

# E12497



## Connecting cable with socket

ADOGD040ZDS0020H04



| Application             |      |                             |
|-------------------------|------|-----------------------------|
| Special feature         |      | Gold-plated contacts        |
| Design                  |      | power cable, T-coded        |
| Electrical data         |      |                             |
| Operating voltage       | [V]  | < 60 DC                     |
| Max. current load total | [A]  | 12                          |
| Operating conditions    |      |                             |
| Ambient temperature     | [°C] | -25...85                    |
| Protection              |      | IP 67                       |
| Mechanical data         |      |                             |
| Weight                  | [g]  | 2053.5                      |
| Dimensions              | [mm] | 15.4 x 15.4 x 52.8          |
| Materials               |      | PP                          |
| Moulded-body material   |      | TPU                         |
| Material nut            |      | diecast zinc, nickel-plated |
| Remarks                 |      |                             |
| Pack quantity           |      | 1 pcs.                      |

# E12497



## Connecting cable with socket


ADOGD040ZDS0020H04

### Electrical connection


Cable: 20 m, PUR, black, Ø 8 mm; 4 x 1.5 mm²

### Electrical connection - socket

Connector: 1 x M12, straight; coding: T; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated

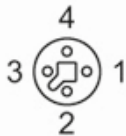

### Connection

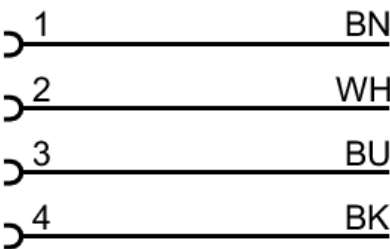

BK = Core colours :  
BN = black  
BU = brown  
WH = blue  
BK = white