


E12514



Ethernet RJ45 connector

RJ45-Steckverbinder

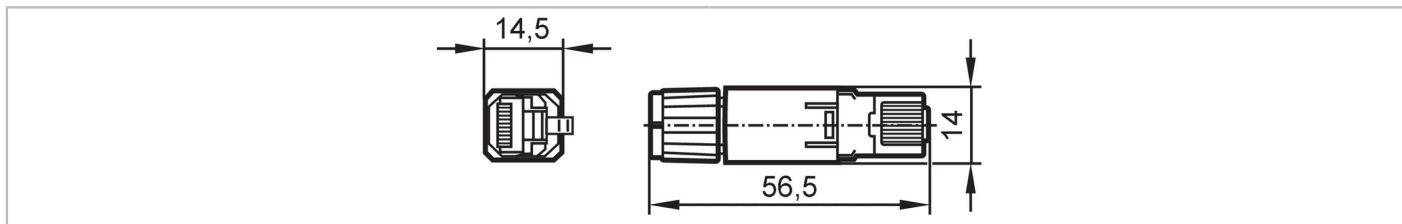

Application

Application: Industrial applications / factory automation

Operating conditions

Ambient temperature [°C]: -10...60

Protection: IP 20

Mechanical data

Weight [g]: 10.4

Remarks


Pack quantity: 1 pcs.

Electrical connection

insulation displacement terminals: 0.34 mm²; Cable sheath: Ø 4.5...8 mm; AWG 22

Electrical connection - plug

Connector: 1 x RJ45, straight; Contacts: 8

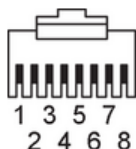

Connection

