


# E12514



## Ethernet RJ45 connector

RJ45-Steckverbinder

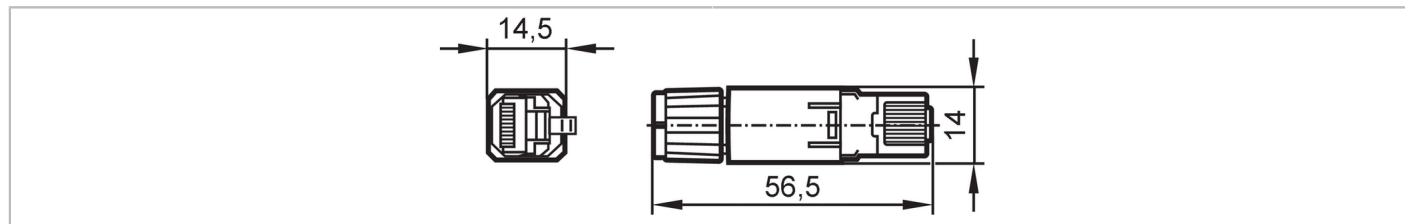

### Operating conditions

Ambient temperature	[°C]	-10...60
Protection		IP 20

### Mechanical data

Weight	[g]	10.4
--------	-----	------

### Remarks


Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection

insulation displacement terminals: 0.34 mm<sup>2</sup>; Cable sheath: Ø 4.5...8 mm; AWG 22

### Electrical connection - plug

Connector: 1 x RJ45, straight; Contacts: 8

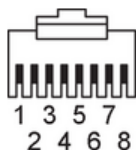

### Connection

