


## Mounting set for manual valves and ball valves

MOUNTING KIT FOR MANUAL VALVES F16/M10

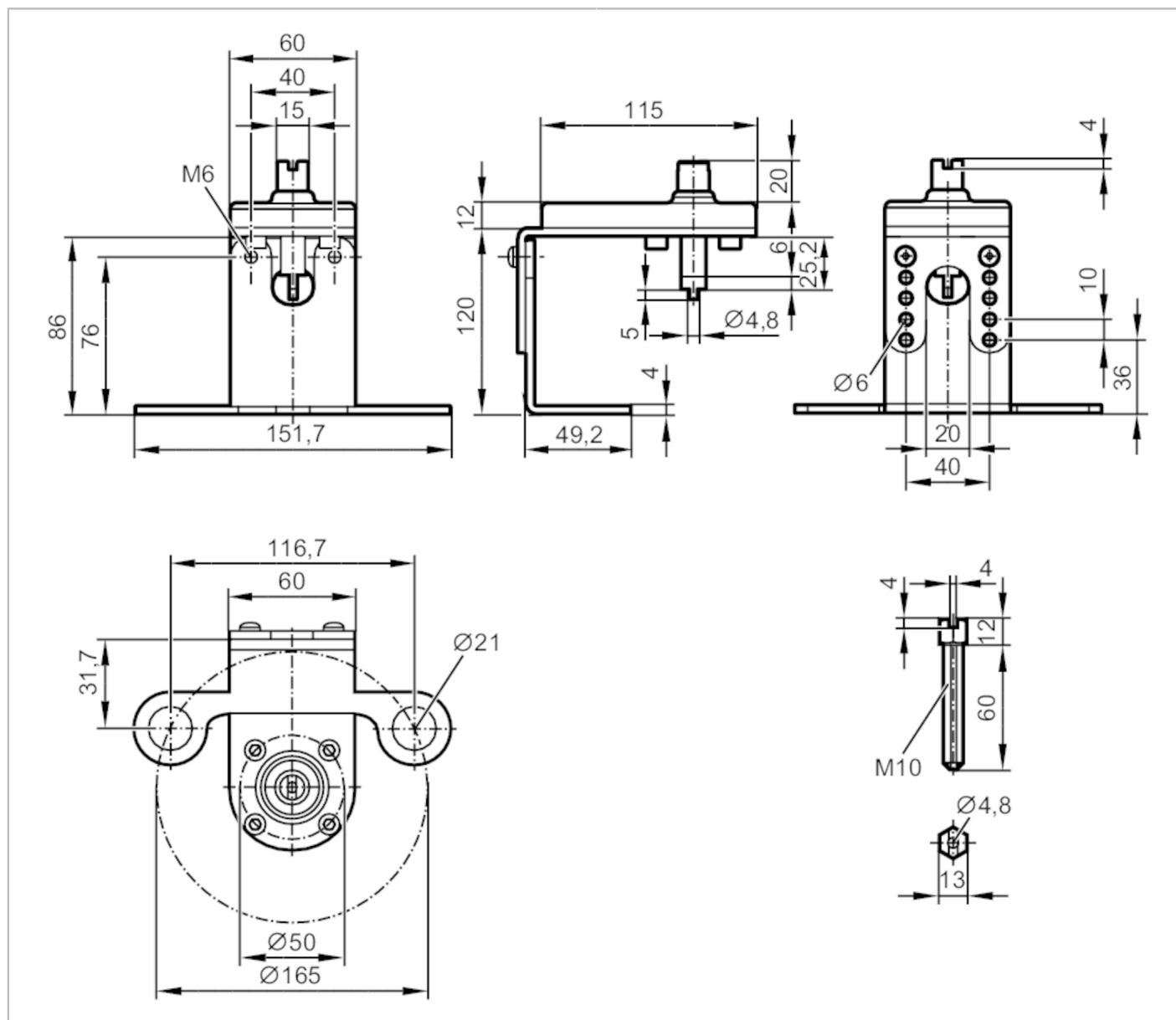

Application		
Design		for types IND, INE
Operating conditions		
Ambient temperature	[°C]	-30...80
Mechanical data		
Weight	[g]	716
Top flange diameter	[mm]	165
ISO top flange type		F16
Shaft extension		M10
Materials	Mounting plate: plastics; metal parts: stainless steel (304/1.4301)	
Remarks		
Pack quantity	1 pcs.	