


E12289



Wirable plug

SSTGN040ZDSFKSG

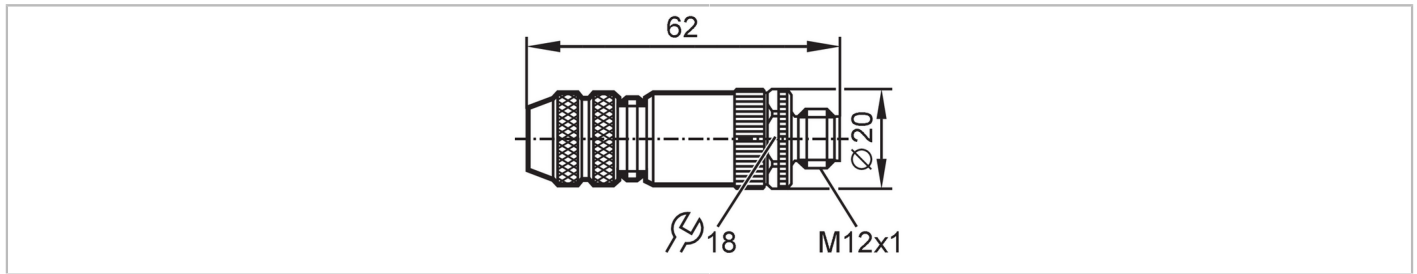

Application

Special feature	Free from silicone; Gold-plated contacts
Design	Ethernet cable, D-coded
Application	Industrial applications / factory automation
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	44.6
Dimensions	[mm]	20.2 x 20.2 x 63
Moulded-body material		diecast zinc, nickel-plated
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm; AWG 18

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: diecast zinc, nickel-plated; Locking: diecast zinc, nickel-plated; Shielded connection cable: shieldable



Connection

