


# E18104



## Connecting cable with socket

ADOGH040VAS0100E04

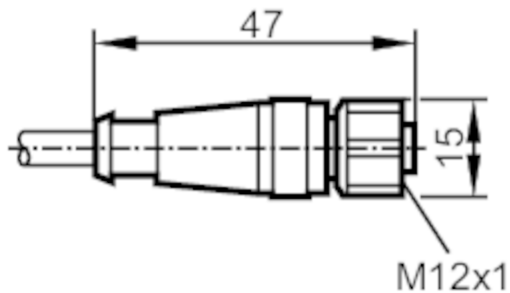

| Application           |      |                                |
|-----------------------|------|--------------------------------|
| Special feature       |      | Gold-plated contacts           |
| Electrical data       |      |                                |
| Operating voltage     | [V]  | < 300 AC/DC                    |
| Operating conditions  |      |                                |
| Ambient temperature   | [°C] | -20...105                      |
| Protection            |      | IP 68                          |
| Mechanical data       |      |                                |
| Weight                | [g]  | 3764.814                       |
| Dimensions            | [mm] | 15 x 15 x 47                   |
| Materials             |      | PVC                            |
| Moulded-body material |      | PVC                            |
| Material nut          |      | stainless steel (316Ti/1.4571) |
| Remarks               |      |                                |
| Pack quantity         |      | 1 pcs.                         |

# E18104



## Connecting cable with socket


ADOGH040VAS0100E04

### Electrical connection


Cable: 100 m, PVC, grey, Ø 5 mm; 4 x 0.34 mm<sup>2</sup> / AWG 22

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

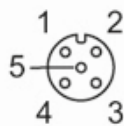

### Connection

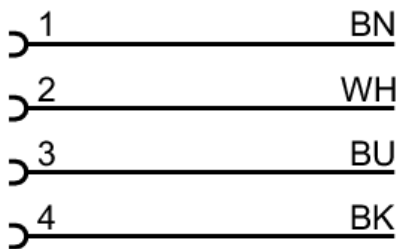

5: not used  
Core colours :  
BK = black  
BN = brown  
BU = blue  
WH = white