




Fibre optic through-beam sensor

FE-00-M-V-E1/2,5m

Article no longer available - archive entry

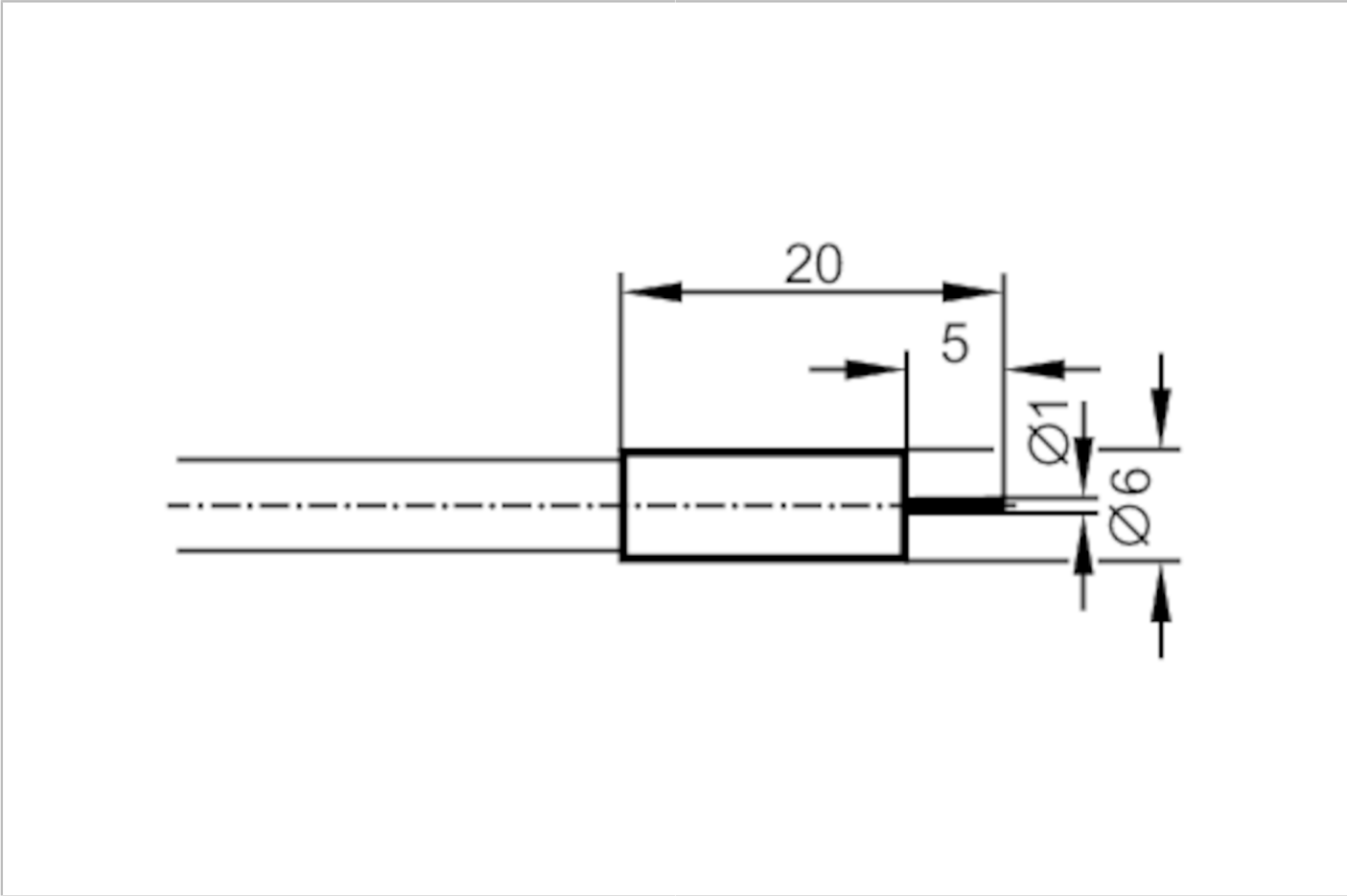

Application		
Function principle		Through-beam sensor
Detection zone		
Range with fibre-optic amplifier type		OKF; OUF
OKF		
Range of fibre optics	[mm]	36
OUF		
Range of fibre optics	[mm]	36
Operating conditions		
Ambient temperature	[°C]	-20...150
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	1
Sensing head length	[mm]	5
Total length	[mm]	2500
Min. bending radius	[mm]	20
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)

E20549



Fibre optic through-beam sensor

FE-00-M-V-E1/2,5m

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.