




Fibre optic diffuse reflection sensor

FT-30-P-A-R8

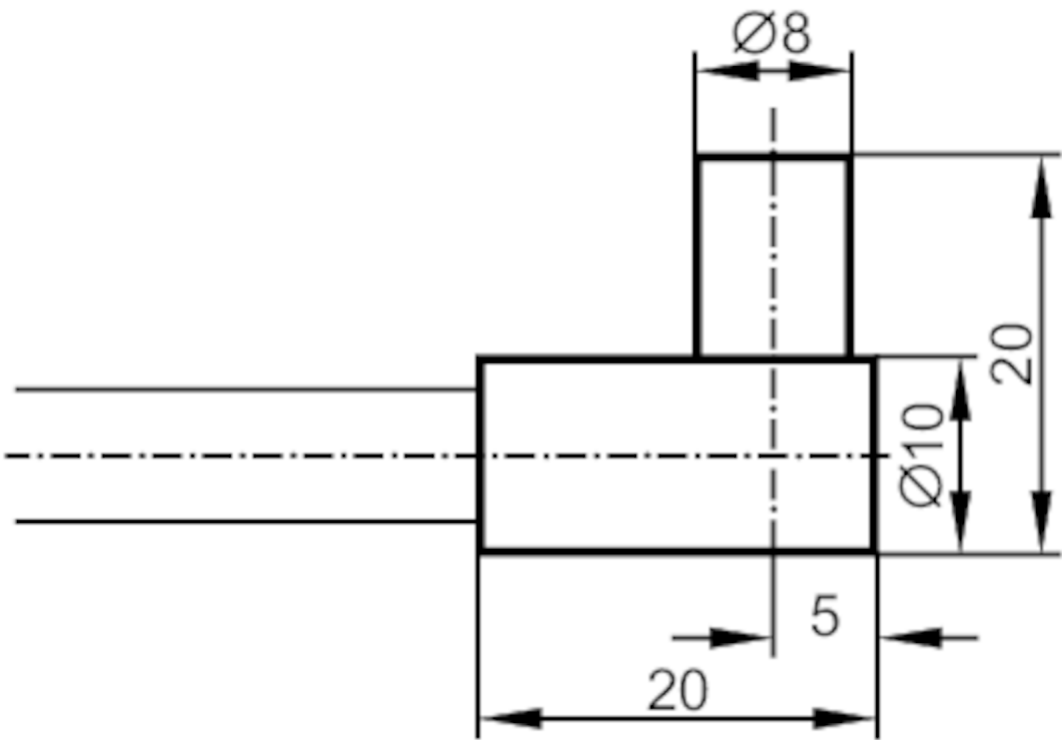

Application		
Function principle		Diffuse reflection sensor
Application		For use in industrial environments
Detection zone		
Range with fibre optic amplifier type		OIF
OIF		
Range fibre optics	[mm]	70
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	91
Version of sensing head		angled
Sensing head diameter	[mm]	8
Total length	[mm]	600
Min. bending radius	[mm]	30
Fibre arrangement		⓪
Materials		Adapter: PA
Fibre material		glass
Fibre head material		aluminium

E20157



Fibre optic diffuse reflection sensor

FT-30-P-A-R8

Fibre sheath material	PVC
Accessories	
Items supplied	E20353
Remarks	
Pack quantity	1 pcs.