


Fibre optic diffuse reflection sensor

FT-30-P-A-M8/1M

Article no longer available - archive entry

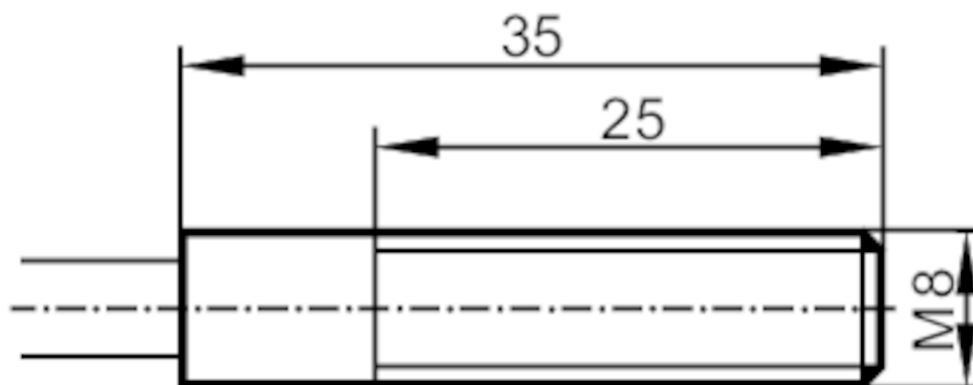

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics

[mm]

70

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M8

Total length

[mm]

1000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

PVC

E20174



Fibre optic diffuse reflection sensor

FT-30-P-A-M8/1M

Remarks	
---------	--

Pack quantity	1 pcs.
---------------	--------