


Fibre optic diffuse reflection sensor

FT-00-R3

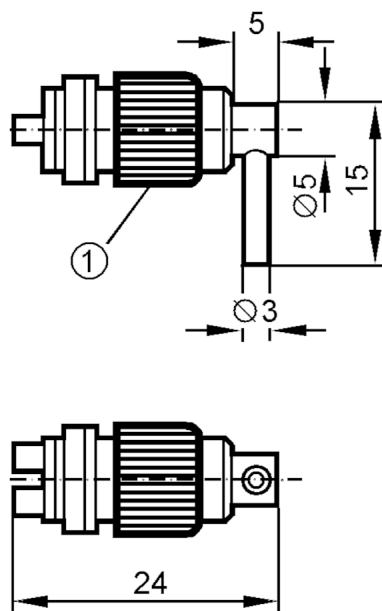

- 1 Lock nut
2 OKF with fibre optics

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF

OKF

Range fibre optics

[mm]

25

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

14

Version of sensing head

angled; with adapter for direct mounting

Sensing head diameter

[mm]

3

Total length

[mm]

24

Fibre arrangement



Materials

Lock nut: plastics

Fibre material

glass

Fibre head material

stainless steel (1.4305 / 303)

Remarks

Pack quantity

1 pcs.