


Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

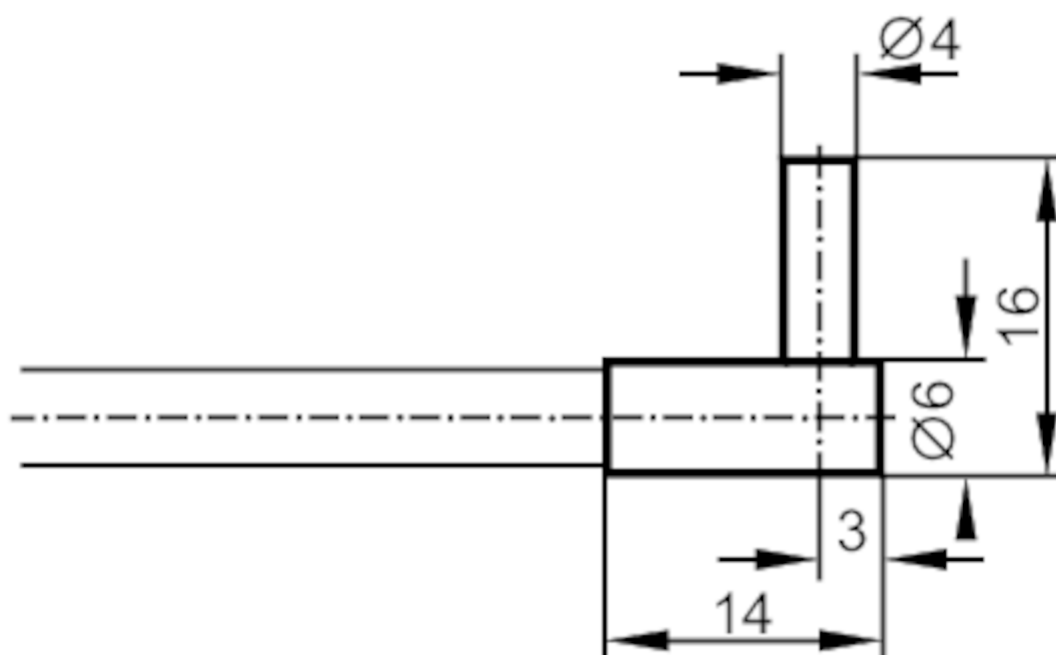

Application

Function principle	Diffuse reflection sensor
Application	For use in industrial environments

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	36
-------------------------	----

OUF

Range fibre optics [mm]	36
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Weight [g]	68.5
Version of sensing head	angled
Sensing head diameter [mm]	4
Sensing head length [mm]	10
Total length [mm]	1500
Min. bending radius [mm]	20
Fibre arrangement	Ⓢ

E20351



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.