




Fibre optic through-beam sensor

FE-18-A-A-M4

Article no longer available - archive entry

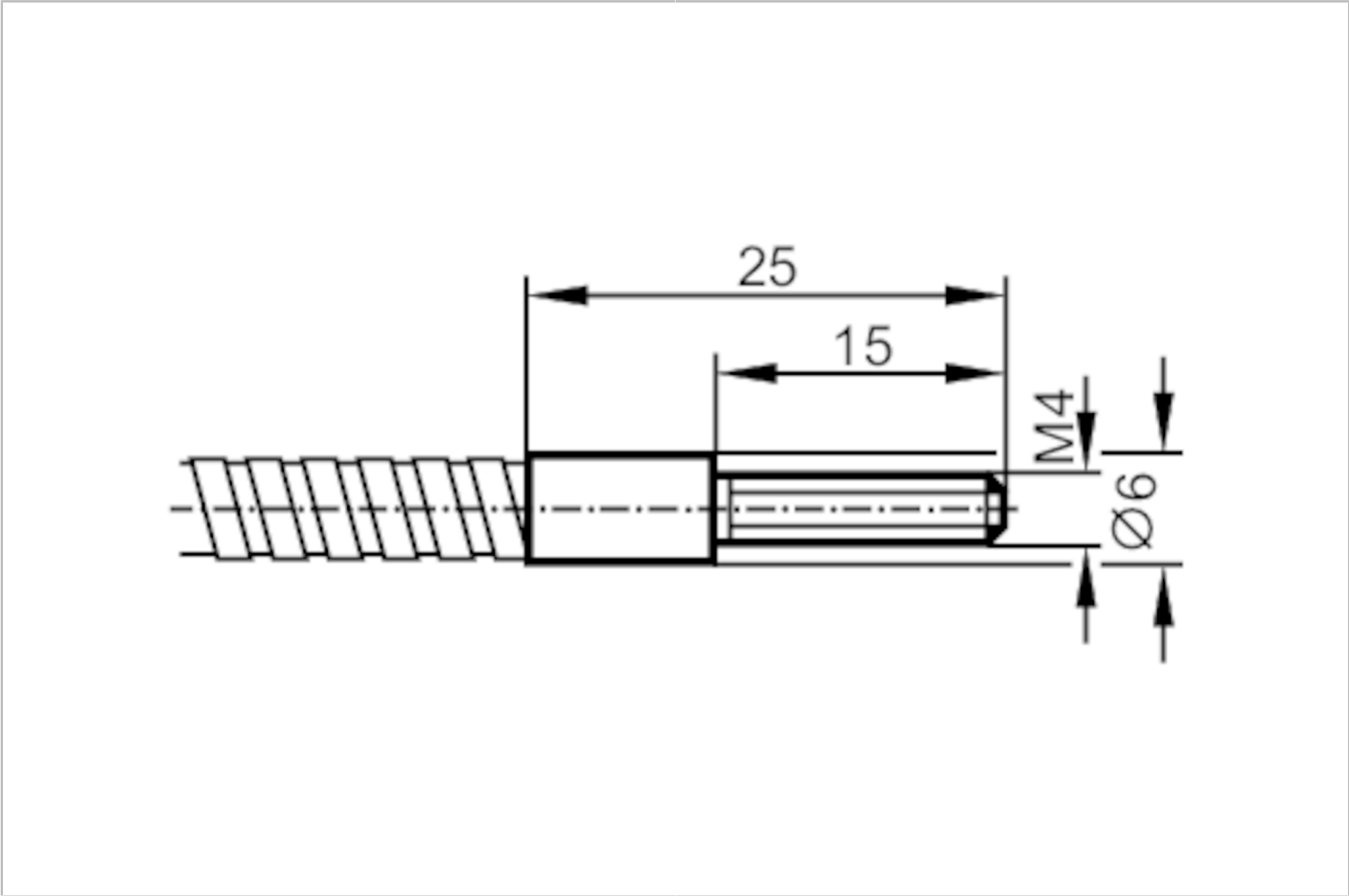

Application		
Function principle		Through-beam sensor
Detection zone		
Range with fibre-optic amplifier type		OGF
OGF		
Range of fibre optics	[mm]	80
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	0.059
Version of sensing head		straight
Sensing head thread		M4
Sensing head length	[mm]	15
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		●
Materials		Adapter: PPE
Fibre material		glass

E20389



Fibre optic through-beam sensor

FE-18-A-A-M4

Fibre head material	aluminium
Fibre sheath material	aluminium
Accessories	
Items supplied	hexagon nuts: 4 x M4
	tooth lock washers: 4
Remarks	
Pack quantity	1 pcs.