


# E35010



## Thermowell for temperature sensors

THERMOWELL D10/G1/2/L=100

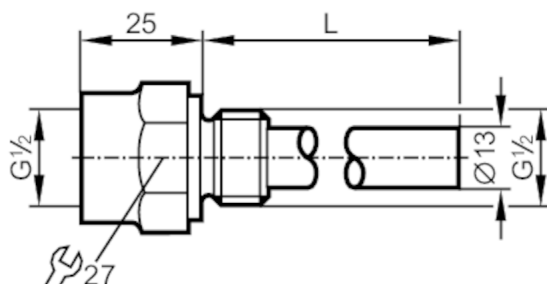

Application	
Pressure rating	[bar] 16
Measuring/setting range	
Probe length L	[mm] 82
Mechanical data	
Weight	[g] 128.8
Materials	stainless steel (1.4404 / 316L)
Sensor connection	G 1/2 Ø 10 mm
Process connection	G 1/2
Remarks	
Pack quantity	1 pcs.