


# E40170



## Pipe section for compressed air meter

MESSSTR DN40/L475/VA/D49

Article no longer available - archive entry

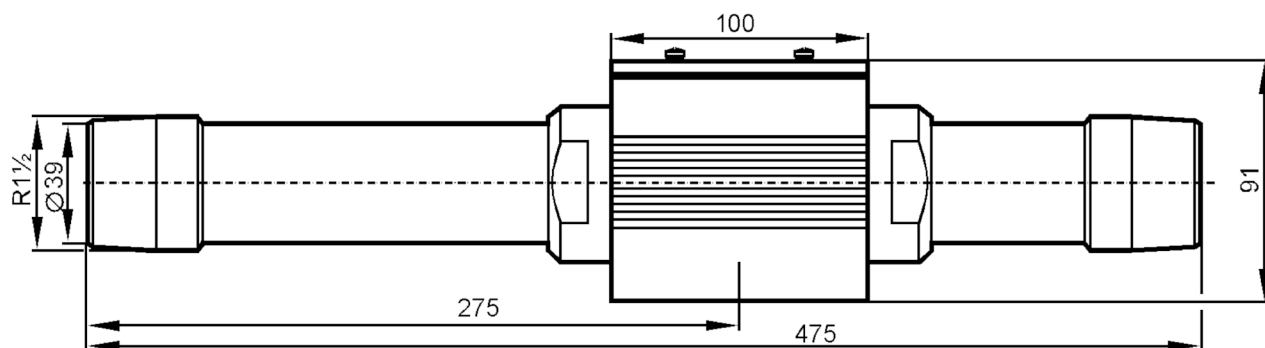

### Application

Design	for compressed air meters SD9
Pressure rating [bar]	16

### Mechanical data

Materials	stainless steel (1.4301 / 304); FKM; aluminium anodised
Process connection	R 1 1/2

### Remarks

Pack quantity	1 pcs.
---------------	--------