


# E60124



## Wirable socket

SDOGK120--LFKSG

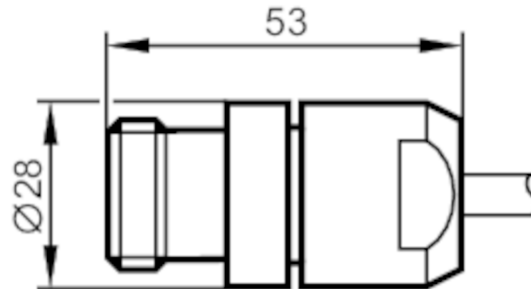

### Electrical data

Operating voltage [V] 4.5...30 DC

### Operating conditions

Ambient temperature [°C] -40...125

Protection IP 67

### Mechanical data

Weight [g] 45

Dimensions [mm] 28 x 28 x 53

Materials brass in plastic sheath; PA 6.6 black

Moulded-body material brass / PA 6.6, in plastic sheath

### Remarks


Pack quantity 1 pcs.

### Electrical connection

soldering: ...1 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath

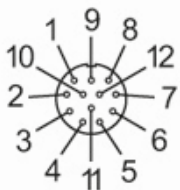

# E60124



## Wirable socket

SDOGK120--LFKSG

### Connection

