


E70588



AS-Interface power distributor


QUAD M12 AS-i/24V 4A

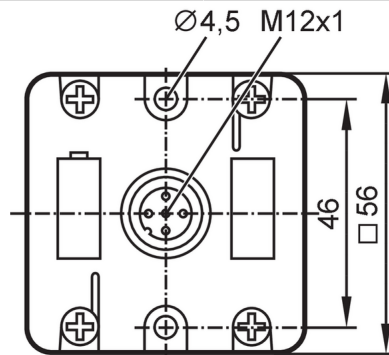

Application	
Design	AS-i / 24 V
Electrical data	
Operating voltage [V]	26.5...31.6 DC
Max. current load total [A]	2
Additional voltage supply [V]	24 DC
Operating conditions	
Ambient temperature [°C]	-25...75
Protection	IP 65
Mechanical data	
Weight [g]	95.5
Materials	PA 6.6; socket: stainless steel (316L/1.4404); screws: stainless steel (316L/1.4404); nut: stainless steel (316L/1.4404); O-ring: NBR; flat cable seal: NBR
Remarks	
Pack quantity	1 pcs.

Electrical connection

 Connector: M12; coding: A



1	AS-i +
2	0V
3	AS-i -
4	+24V
5	functional earth