


E70129



Jumper cable with valve plug

VDAA0401--S0002A03STA030MSS

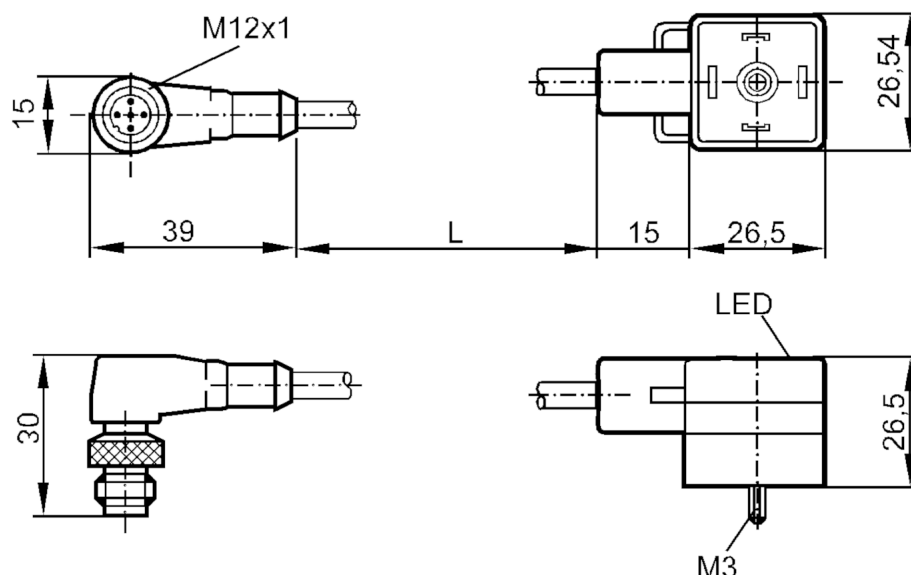

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage [V]	< 24 AC/DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Weight [g]	138.5
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Accessories	
Items supplied	screw panel for labelling
Remarks	
Pack quantity	1 pcs.




Jumper cable with valve plug

VDAA0401--S0002A03STAH030MSS

Electrical connection - socket

 
Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

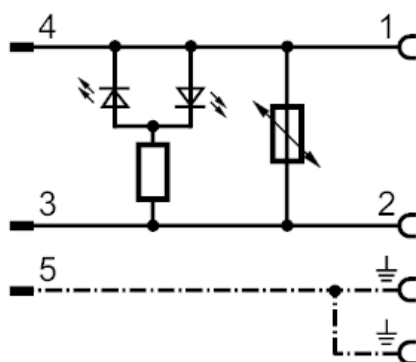

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

