




RFID tag

ID-TAG/D30x20/01

Article no longer available - archive entry

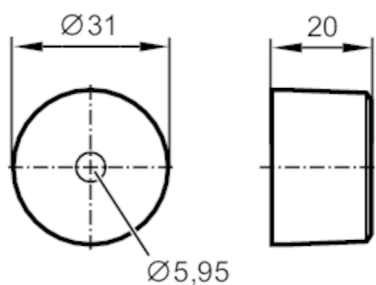

Application

Operating temperature (active)	[°C]	-25...85
--------------------------------	------	----------

Electrical data

Operating frequency	[MHz]	0,125
Memory size	[bit]	363
Max. read cycles		unlimited
Max. write cycles		100000

Operating conditions

Ambient temperature	[°C]	-25...85
Storage temperature	[°C]	-25...180

Mechanical data

Weight	[g]	23
Dimensions	[mm]	Ø 30 / L = 20
Materials		PU

Remarks

Remarks	180 °C für max. 30 min Kumulierte Temperaturbeständigkeit ca. 100 h über 150 °C
Pack quantity	1 pcs.