


EBC012



Splitter box

ZDO8H05HMSS0000-00STAK190MSS

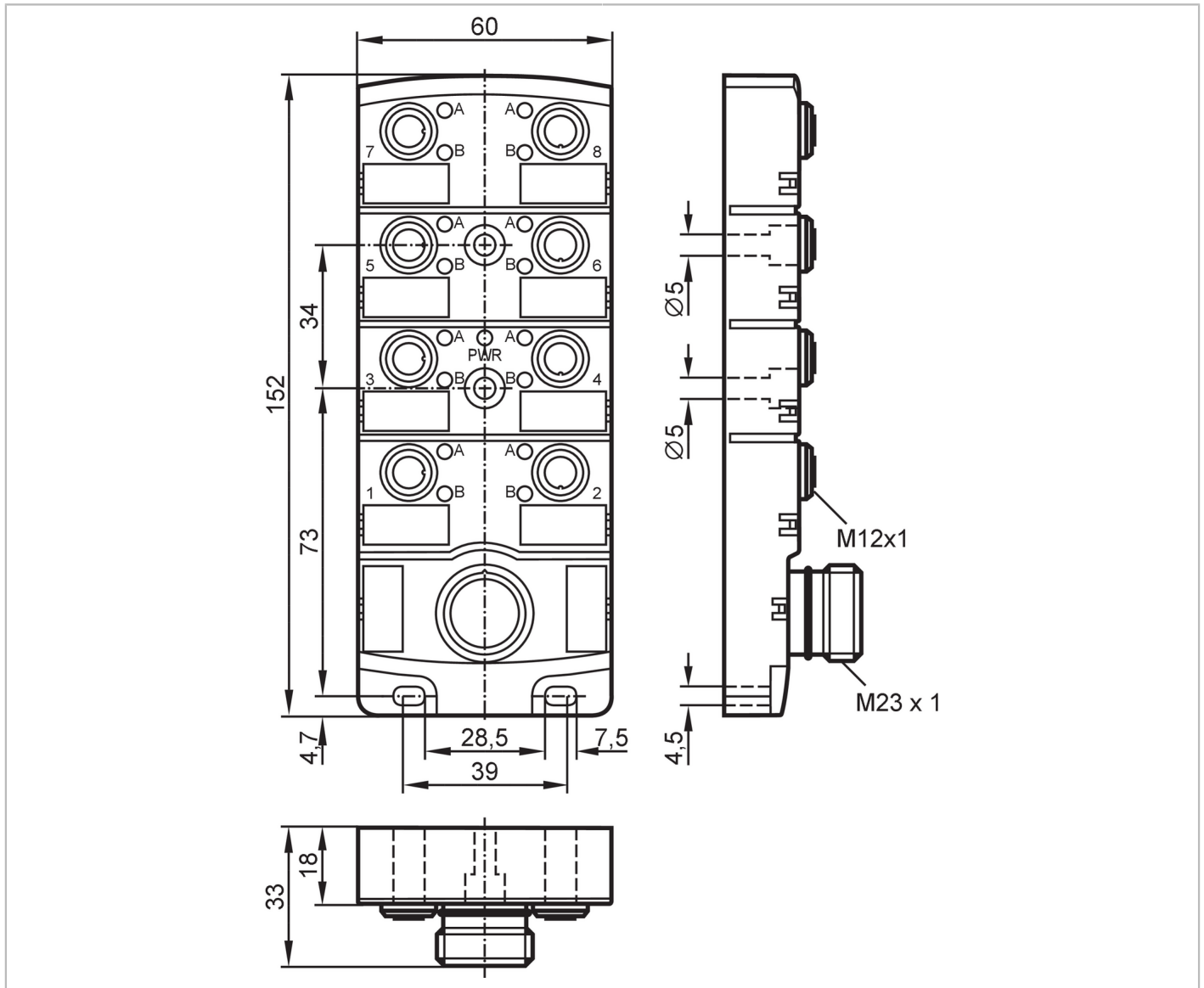

Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	10...30 DC; ("supply class 2" to cULus)
Max. current load per module/slot [A]	4
Max. current load total [A]	10
Outputs	
Electrical design	PNP
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 67



Splitter box


ZDO8H05HMSS0000-00STAK190MSS

Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight [g]		306
Housing		rectangular
Type of mounting		backplane mounting
Dimensions [mm]		152 x 60 x 33
Materials		housing: PA
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green
Accessories		
Items supplied		Protective caps: 2
		labels: 8
Remarks		
Pack quantity		1 pcs.
Electrical connection - Connection		
Connector: 1 x M23; Contacts: 19, gold-plated; Tightening torque: 0.8...1.5 Nm		

Splitter box

ZDO8H05HMSS0000-00STAK190MSS

Connection

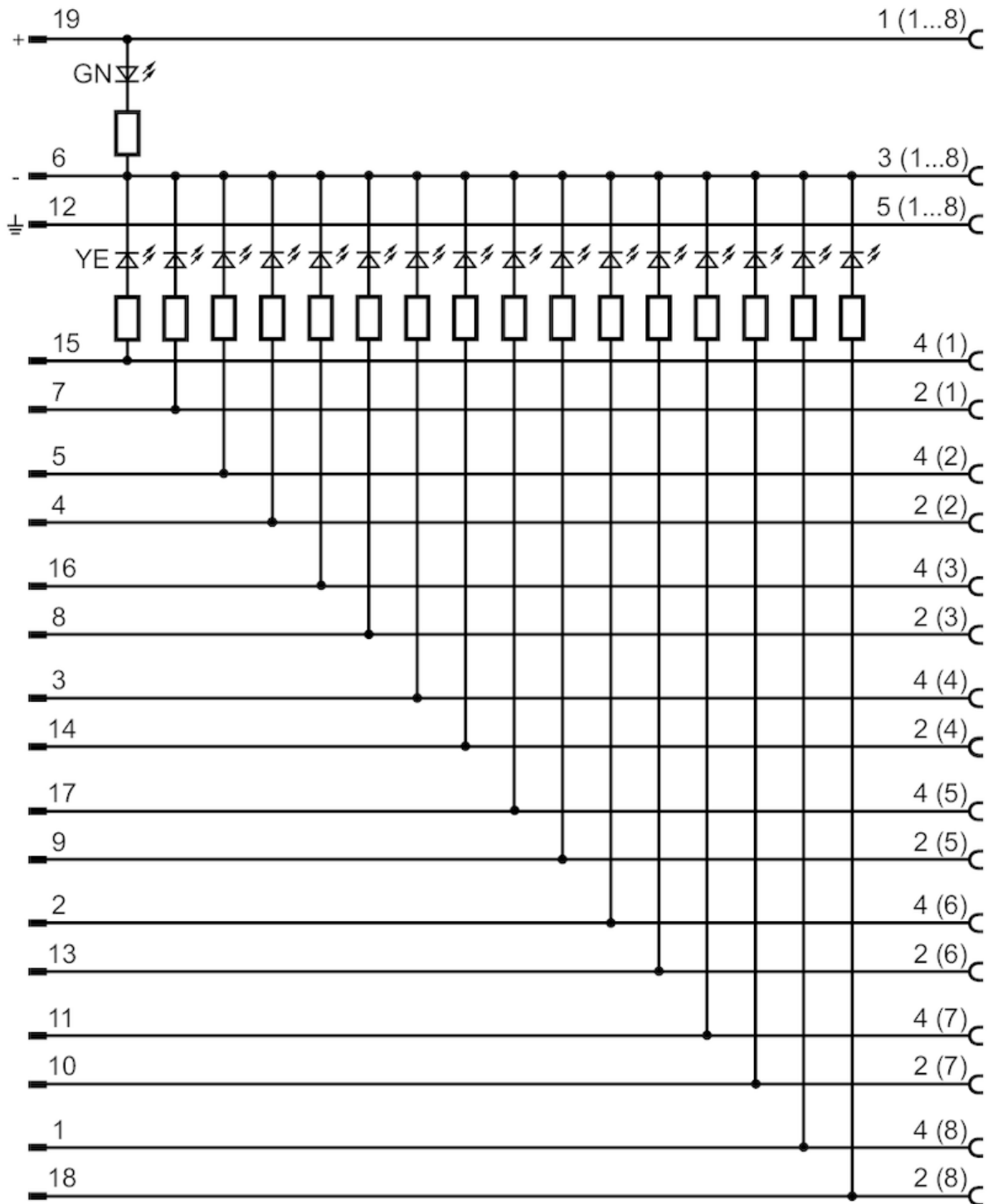

Electrical connection - slot

Connector: 8 x M12; coding: 5; Contacts: A, gold-plated; Tightening torque: 0.8...1.5 Nm

