


EBC012



Splitter box

ZDO8H05HMSS0000-00STAK190MSS

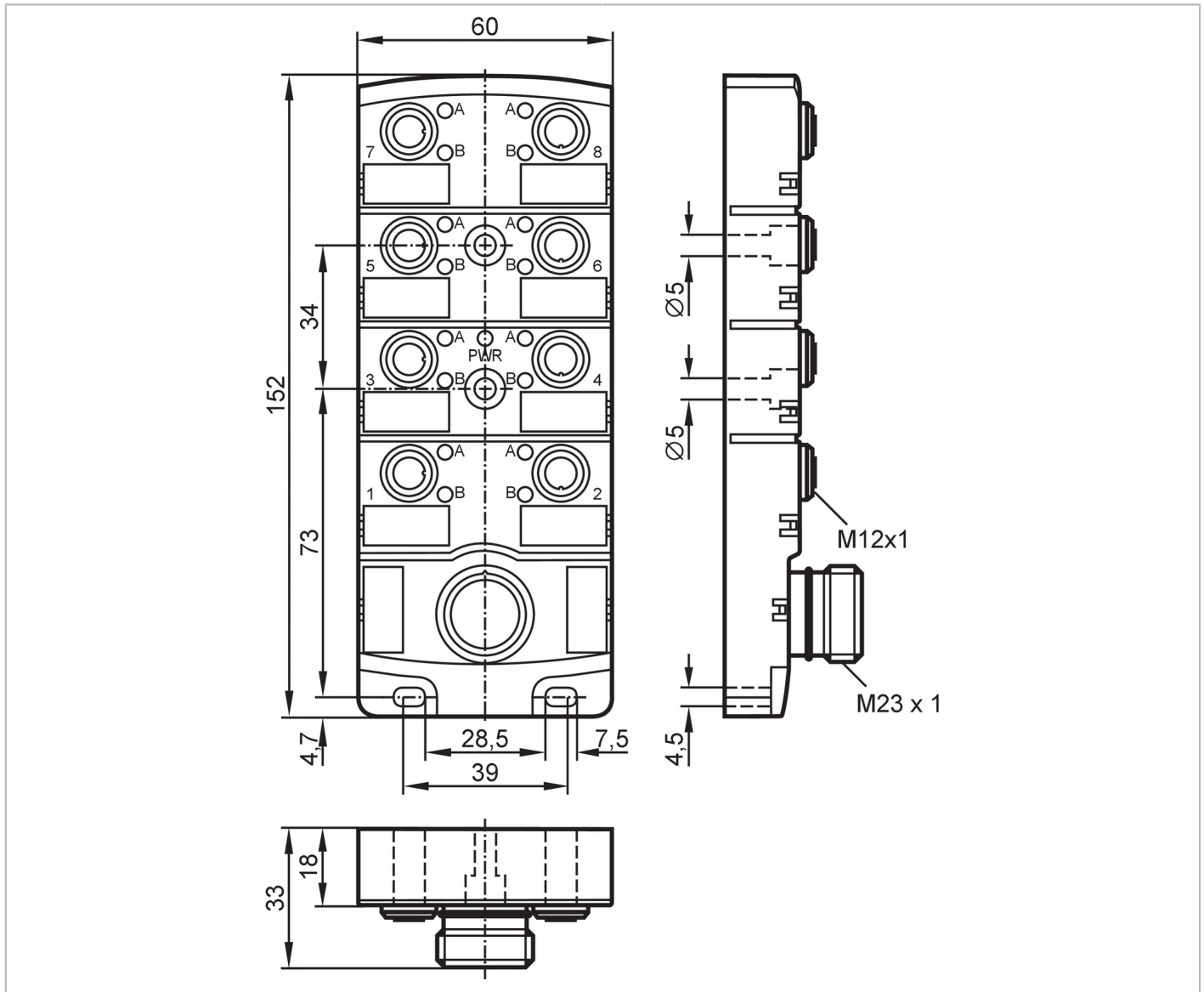

Application		
Special feature		Free from silicone; Gold-plated contacts
Application		Industrial applications / factory automation; Use in machine tools, coolants and lubricants
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...80

EBC012



Splitter box

ZDO8H05HMSS0000-00STAK190MSS

Protection	IP 67
------------	-------

Tests / approvals

UL approval	Enclosure type	Type 1
-------------	----------------	--------

Mechanical data

Weight [g]	306
Housing	rectangular
Type of mounting	backplane mounting
Dimensions [mm]	152 x 60 x 33
Materials	housing: PA
Number of ports splitter box	8
Connector type	M12

Displays / operating elements

Display	switching status	16 x LED, yellow
	operation	1 x LED, green

Accessories


Items supplied	Protective caps: 2 labels: 8
----------------	---------------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Contacts: 19, gold-plated; Tightening torque: 0.8...1.5 Nm

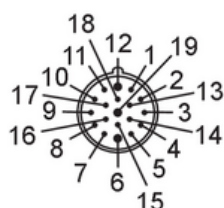


EBC012



Splitter box

ZDO8H05HMSS0000-00STAK190MSS

Connection

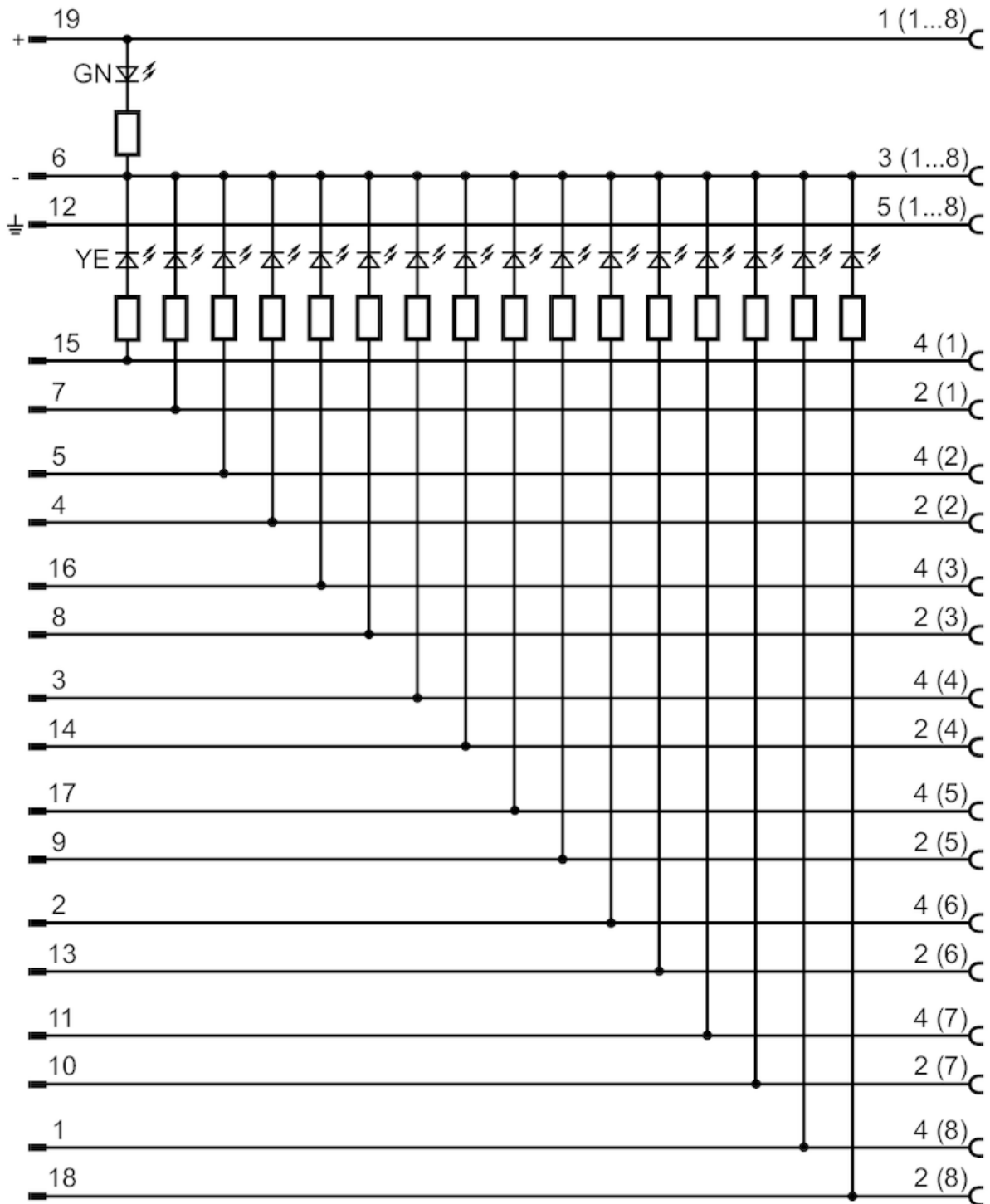

Electrical connection - slot

Connector: 8 x M12; coding: A; Contacts: 5, gold-plated; Tightening torque: 0.8...1.5 Nm

