


EBC112



Y-splitter

ZDO2F030MSS0000-00STGH040MSS

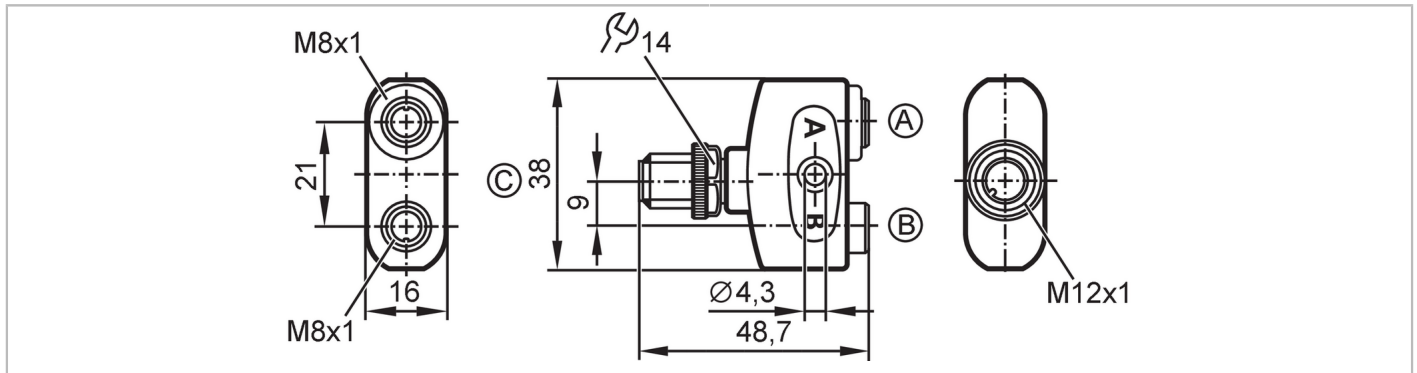

Application

Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes

Electrical data

Operating voltage [V]	< 50 AC / < 60 DC; (cULus: 30 AC / 42 DC)
Protection class	III
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...90
Note on ambient temperature	cULus: ...65 °C
Protection	IP 65; IP 67; IP 68; IP 69K

Tests / approvals

UL approval	voltage supply	Class 2
	File number UL	E191684

Mechanical data

Weight [g]	30.2
Materials	housing: PA orange
Material nut	brass, nickel-plated
Sealing material	FKM

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug C

Connector: 1 x M12; coding: A; Contacts: 4, gold-plated; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm




EBC112



Y-splitter

ZDO2F030MSS0000-00STGH040MSS

Connection

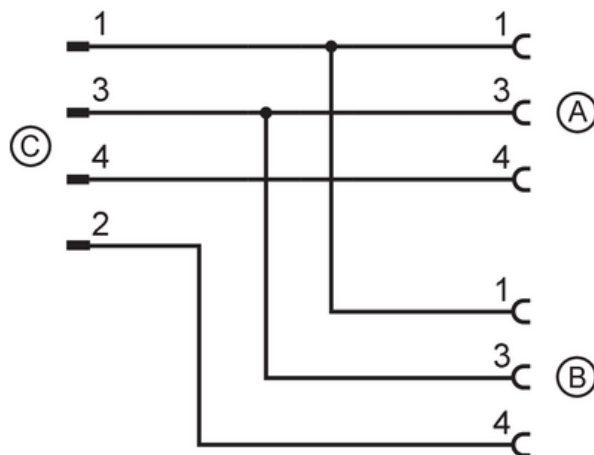

Electrical connection - socket A/B

Connector: 2 x M8; coding: A; Contacts: 3, gold-plated; Locking: brass, nickel-plated; Sealing: FKM; Tightening torque: 0.3...0.5 Nm

