


# E12387



## Connecting cable with socket

ADOGH080VAS0025E08

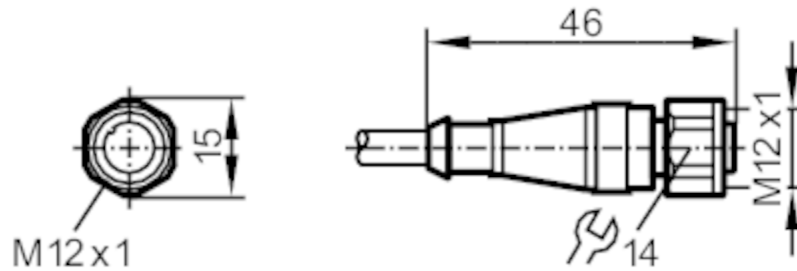

### Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	2

### Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

### Mechanical data

Weight	[g]	1612.5
Dimensions	[mm]	15 x 15 x 46
Materials		PVC
Material nut		stainless steel (1.4404 / 316L)

### Remarks

Notes	For 8-pole sockets the core colours are not standardised.; Please note the wiring of the sensor and the sockets (see data sheet).
Pack quantity	1 pcs.

### Electrical connection

Cable: 25 m, PVC, orange, Ø 5.9 mm; 8 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

# E12387



## Connecting cable with socket

ADOGH080VAS0025E08



### Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

colours to DIN 47100

Core colours :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow