


Y-splitter

ZDO2H040VAS0000-00STGH050VAS

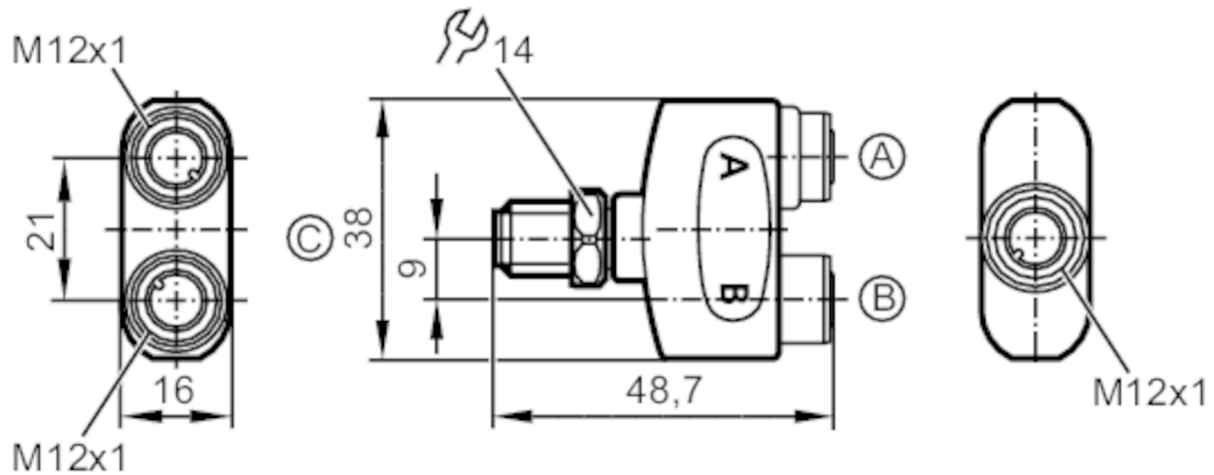

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Protection class	II
Max. current load per module/slot [A]	4
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...100
Note on ambient temperature	cULus: ...65 °C
Storage temperature [°C]	-25...55
Storage humidity [%]	10...100
Other climatic conditions for storage according to stated class	1K22/ DIN 60721-3-1
Protection	IP 65; IP 67; IP 68; IP 69K

Tests / approvals

UL approval	power supply	Class 2
	File number UL	E191684

Mechanical data

Weight [g]	35.7
Materials	housing: PA orange; Sealing: EPDM

EBT010



Y-splitter

ZDO2H040VAS0000-00STGH050VAS

Material nut

stainless steel (1.4404 / 316L)


Remarks

Pack quantity


1 pcs.

Electrical connection - plug

Connector: 1 x M12; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

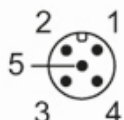

Connection

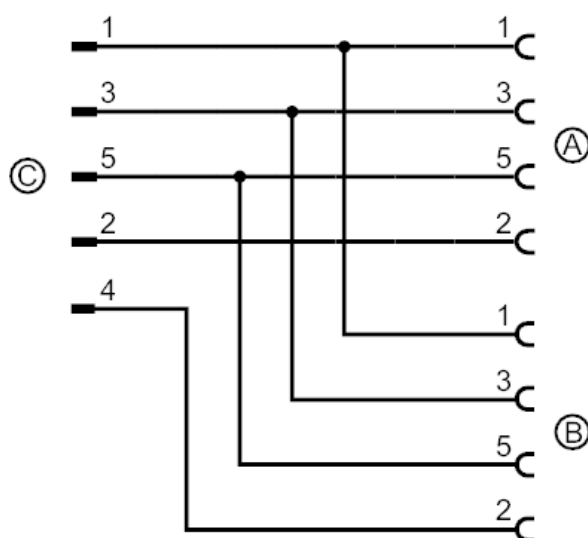

connection to IEC 61076-2-101

Electrical connection - socket

Connector: 2 x M12; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

