

# AC1333




## AS-Interface PLC

ControllerE M4 1Master RS232

Article no longer available - archive entry

Alternative article: AC1401 or AC1403 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2019

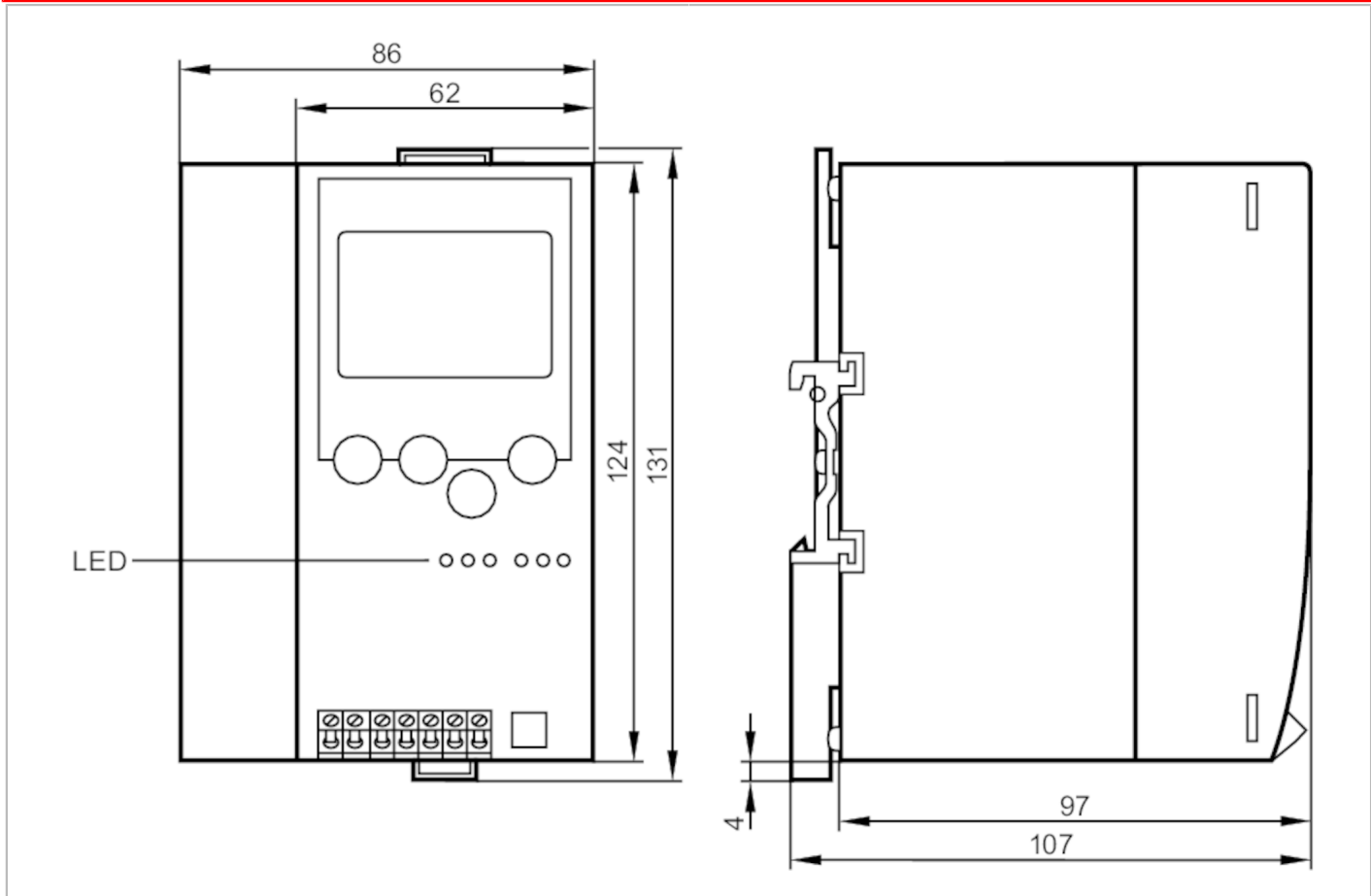

Application	
Application	decentralised controller
Electrical data	
Operating voltage [V]	24 DC
Insulation rating [V]	500
Current consumption [mA]	< 500
Max. current consumption from AS-i [mA]	10
Max. power consumption [VA]	10
Number of AS-i masters	1
Electrical separation	yes
Interfaces	
Communication interface	RS232

# AC1333



## AS-Interface PLC

ControllerE M4 1Master RS232

RS232	
Number of R232 interfaces	1
Transmission rate	9600...115200 Baud
Connector type	RJ11
Usage type	programming
at_schnittstelle-zusatz	electrically isolated

Operating conditions	
Ambient temperature [°C]	0...60
Storage temperature [°C]	-20...70
Protection	IP 20


AS-i classification	
AS-i version	2.1 + 3.0
AS-i profile	M4
AS-i certificate pending	yes

Mechanical data	
Weight [g]	530.5
Housing	housing for DIN rail mounting
Materials	aluminium; steel sheet galvanised

Displays / operating elements		
Display	function	1 x LED, red
		2 x LED, green
		2 x LED, yellow
		full graphic LCD display

Remarks	
Notes	discontinued article
Pack quantity	1 pcs.

Electrical connection	
Connection	

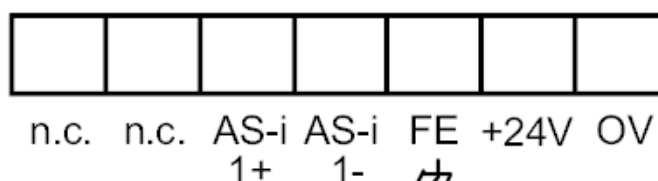

Article no longer available - archive entry

# AC1333

## AS-Interface PLC

ControllerE M4 1Master RS232



Alternative article: AC1401 or AC1403 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2019