



Article no longer available - archive entry

No scale drawing available



Product characteristics

Sensing range	[mm]	4
---------------	------	---

Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Current consumption	[mA]	< 140
---------------------	------	-------

Detection zone

Sensing range	[mm]	4
---------------	------	---

Operating conditions

Ambient temperature	[°C]	-20...70
---------------------	------	----------

Protection		IP 67
------------	--	-------

Tests / approvals

EMC	EN 50081-1	
	EN 61000-6-2	

AS-i classification

AS-i I/O configuration	[hex]	7
------------------------	-------	---

AS-i ID code	[hex]	F
--------------	-------	---

AS-i certificate	15101
------------------	-------

Assignment of the data bits	Designation	Sensor 1	Sensor 2	Dateneingang I1 (Pin 4)	Dateneingang I2 (Pin 2)
-----------------------------	-------------	----------	----------	----------------------------	----------------------------

Mechanical data

Materials	PBT; PC
-----------	---------

Displays / operating elements

Display	operation	1 x LED, green
	function	1 x LED, red

AC2304



AS-Interface dual sensor for pneumatic valve actuators

ASI-MODUL T4 AKTIV 2X2E M12

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: stainless steel




Eingänge

1	Sensorversorgung L+
2	Dateneingang 2 data bit D3
3	Sensorversorgung L-
4	Dateneingang 1 data bit D4

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: stainless steel

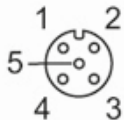

Connection

Elektrischer Anschluss

1	AS-i+
3	AS-i -