


Wirable socket

SDOAT052--SFKPG

Article no longer available - archive entry

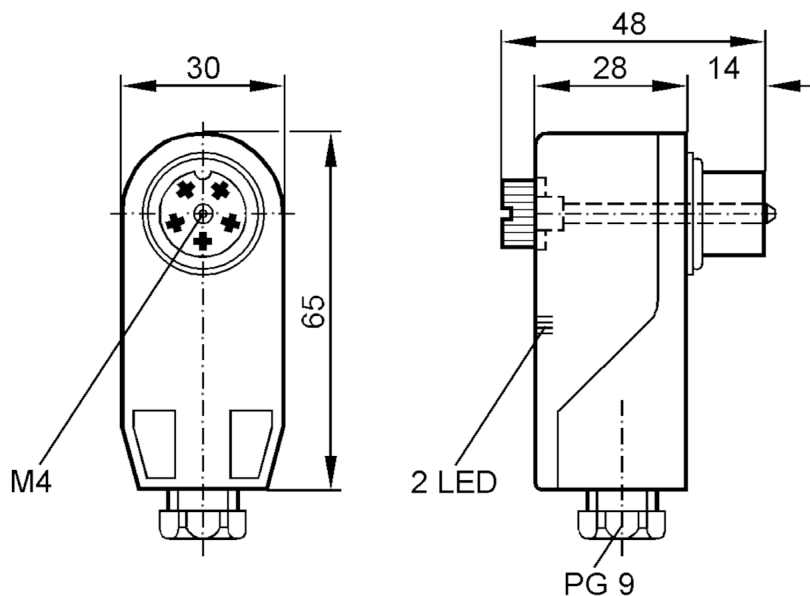

Electrical data

Operating voltage	[M]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	NPN
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-30...80
---------------------	------	----------

Protection	IP 65
------------	-------

Mechanical data

Dimensions	[mm]	48 x 30 x 65
------------	------	--------------

Materials	PA
-----------	----

Moulded-body material	PA
-----------------------	----

Material nut	PA
--------------	----

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10086



Wirable socket

SDOAT052--SFKPG

Electrical connection

terminals: ...1.5 mm²; Cable gland: PG 9

Electrical connection - socket

Connector: 1 x Ø 28 mm, angled; coding: A; Moulded body: PA; Locking: PA



Connection

