


## Connecting cable with socket

ADOAG032--S0010A03

Article no longer available - archive entry

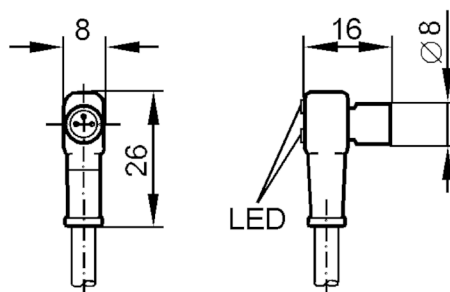

## Application

|                 |              |
|-----------------|--------------|
| Special feature | Halogen-free |
|-----------------|--------------|

## Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
| Protection class  |     | III        |

## Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 65    |

## Mechanical data

|                       |                  |
|-----------------------|------------------|
| Materials             | TPU transparent  |
| Moulded-body material | TPU, transparent |

## Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | switching status | 1 x LED, yellow |
|         | operation        | 1 x LED, green  |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E10289



## Connecting cable with socket


ADOAG032--S0010A03

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

 Connector: 1 x M8, angled; coding: A; Moulded body: TPU, transparent; Locking: snap-in



### Connection



|      |                |
|------|----------------|
| BK = | Core colours : |
| BN = | black          |
| BU = | brown          |
|      | blue           |