


E11601



Adapter socket

EDOGH080MSS00,5E08 (PG9)

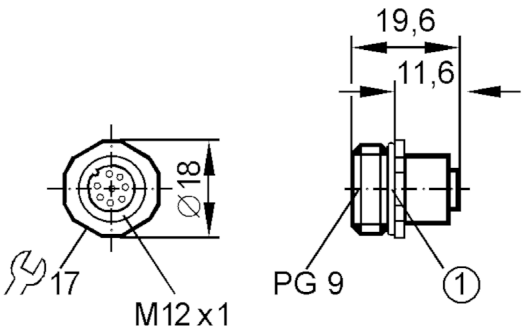

1 O-ring



Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	33
Mounting thread		PG 9
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11601



Adapter socket


EDOGH080MSS00,5E08 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 8 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated

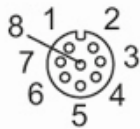

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

colours to DIN
47100

BN =	Core colours : brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow