


E11991



Jumper cable with valve plug

AVDAA031PLS0010H03

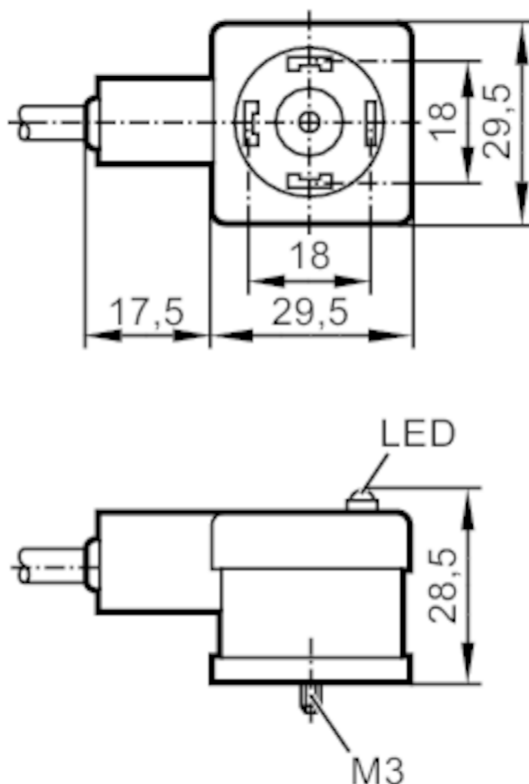

Application		
Special feature	Free from silicone; Halogen-free	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Max. current load total	[A]	5
Operating conditions		
Ambient temperature	[°C]	-20...80
Protection		IP 67
Mechanical data		
Weight	[g]	491.5
Dimensions	[mm]	28.5 x 29.5 x 47
Materials		PP; FKM
Moulded-body material		PP / FPM
Displays / operating elements		
Display	switching status	1 x LED, yellow
Remarks		
Pack quantity	1 pcs.	

E11991



Jumper cable with valve plug


AVDAA031PLS0010H03

Electrical connection


Cable: 10 m, PUR, Halogen-free, Ø 6.6 mm; 3 x 0.5 mm² / AWG 20

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PP / FPM

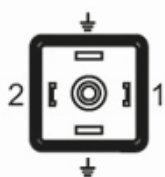

Connection

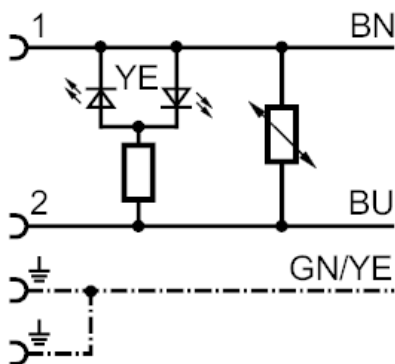

BN = Core colours :
brown
BU = blue
GN/YE = green/yellow