


# E12557



## Connection cable

VDOGS040PLS0002H04DOGS040PLS

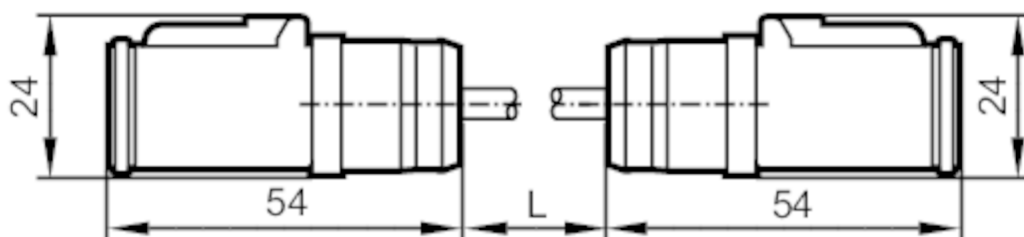

### Application

|                    |                                  |
|--------------------|----------------------------------|
| Special feature    | Free from silicone; Halogen-free |
| Free from silicone | yes                              |

### Electrical data

|                         |     |            |
|-------------------------|-----|------------|
| Operating voltage       | [V] | 12...24 DC |
| Protection class        |     | III        |
| Max. current load total | [A] | 4          |

### Operating conditions

|                              |      |                                      |
|------------------------------|------|--------------------------------------|
| Ambient temperature          | [°C] | -40...85                             |
| Ambient temperature (moving) | [°C] | -30...70                             |
| Protection                   |      | IP 67; (mating connector plugged in) |

### Mechanical data

|                       |     |       |
|-----------------------|-----|-------|
| Weight                | [g] | 173.7 |
| Moulded-body material |     | PA    |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12557



## Connection cable

VDOGS040PLS0002H04DOGS040PLS

### Electrical connection

Cable: 2 m, PUR, Halogen-free, lilac, Ø 6.4 mm; twisted; 2 x 0.50 mm<sup>2</sup> (28 x 0.15 mm) + 2 x 1 mm<sup>2</sup> (52 x 0.15 mm)

### Electrical connection - socket

Connector: 2 x DEUTSCH connector, straight; Moulded body: PA; Contacts: nickel-plated



### Connection

