


E12774



Wirable socket

SDOGB050ZDSFKPG

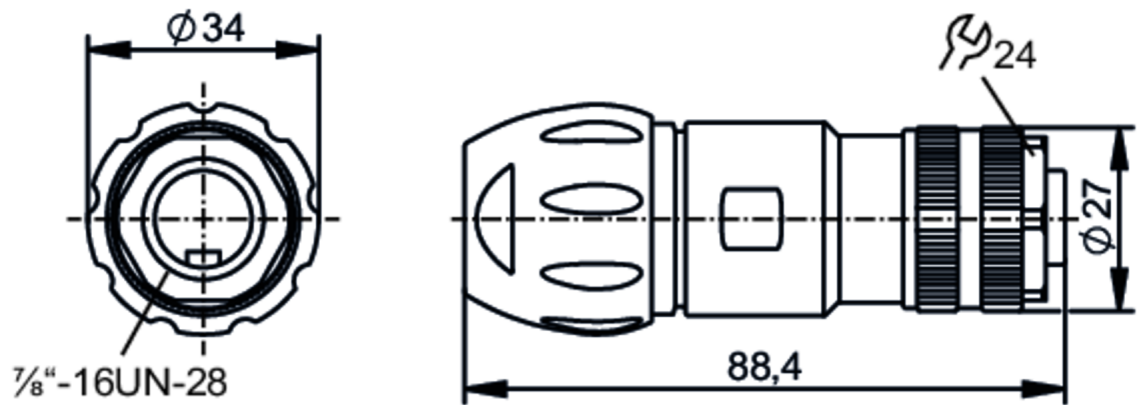

Application		
Special feature	Free from silicone; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 400 AC/DC
Protection class		II
Max. current load total	[A]	9
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	48.808
Moulded-body material		PA; PUR
Material nut		diecast zinc, nickel-plated
Sealing material		NBR
Remarks		
Pack quantity	1 pcs.	

E12774



Wirable socket

SDOGB050ZDSFKPG

Electrical connection

screw terminals: ...1.5 mm²; Cable sheath: Ø 7...13 mm; AWG 16

Electrical connection - socket

Connector: 1 x 7/8", straight; Moulded body: PA; PUR; Locking: diecast zinc, nickel-plated; Sealing: NBR; Contacts: gold-plated



Connection

