


Adapter plug

RSTGH050VAS00.3-05

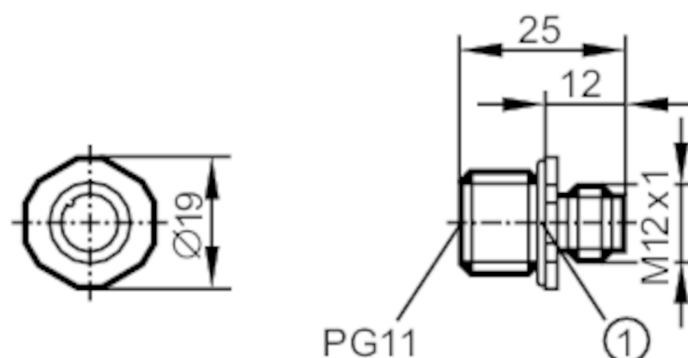

1 O-ring

Electrical data

Operating voltage	[V]	< 250 DC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-20...90
---------------------	------	----------

Mechanical data

Weight	[g]	54.431
Dimensions	[mm]	19 x 19 x 25
Mounting thread		PG 11
Materials		stainless steel (304/1.4301)
Moulded-body material		stainless steel (304/1.4301)

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.5 m, PVC; 5 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: stainless steel (304/1.4301)

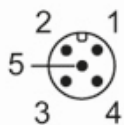

E18102



Adapter plug

RSTGH050VAS00.3-05

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white