


E18251

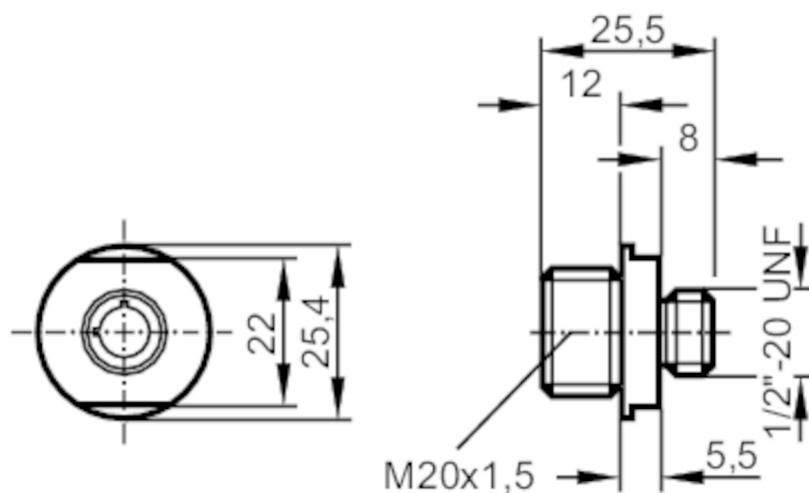

Adapter plug

RSTGA030ALS00.3-03



1 O-ring

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 250 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...80

Protection

IP 68

Mechanical data

Weight

[g]

387.821

Mounting thread

M20 x 1,5

Materials

brass nickel-plated

Moulded-body material

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E18251



Adapter plug

RSTGA030ALS00.3-03

Electrical connection

Cable: 0.3 m, PVC; 3 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x 1/2", straight; coding: C; Moulded body: brass, nickel-plated; Contacts: gold-plated



Connection

1	GN
2	RD/BK
3	RD/WH

BK =	Core colours :
GN =	black
RD =	green
WH =	red
	white