




Adapter socket


RDOGH050MSS00.3E05

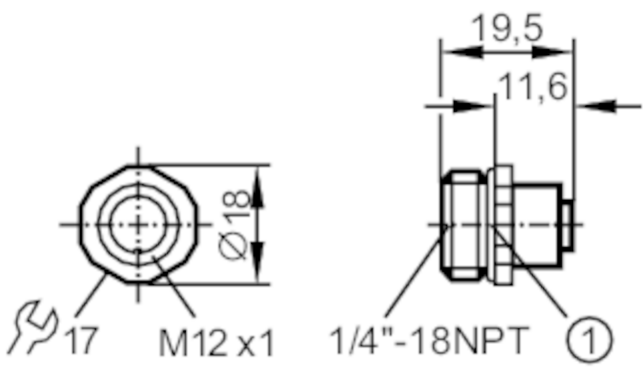

1 O-ring

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	22.68
Mounting thread		1/4"-18NPT
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 0.5 m, PVC; 5 x 0.34 mm²		
Electrical connection - socket		

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated

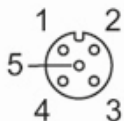


E18327



Adapter socket

RDOGH050MSS00.3E05

Connection

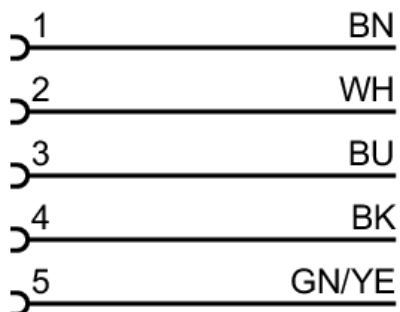

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN/YE =	green/yellow
WH =	white