


Fibre optic through-beam sensor

FE-00-M-V-E3/1,5m

Article no longer available - archive entry

Alternative articles: E20492

When selecting an alternative article and accessories please note that technical data may differ!

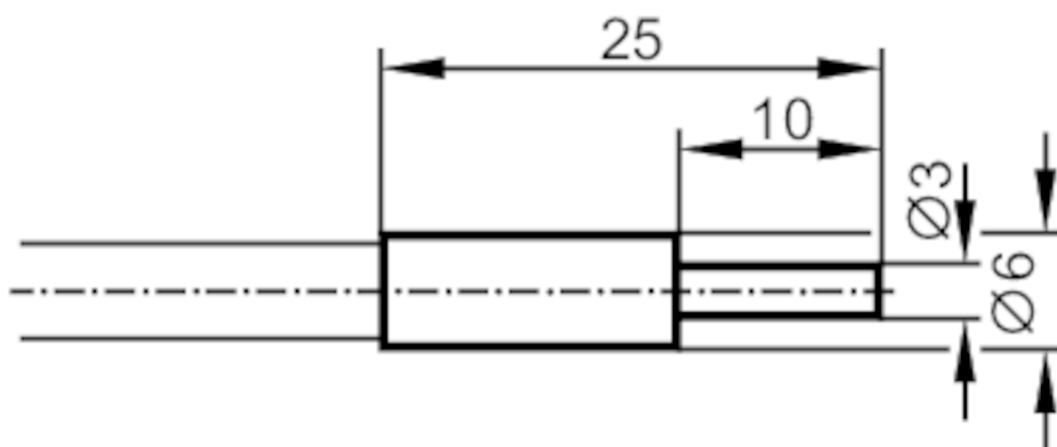

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

108

OUF

Range of fibre optics

[mm]

108

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

1500

E20536



Fibre optic through-beam sensor

FE-00-M-V-E3/1,5m

Min. bending radius	[mm]	20
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)
Fibre sheath material		metal silicone
Remarks		
Pack quantity		1 pcs.