


Fibre optic diffuse reflection sensor

FT-30-N-V-M8

phase-out article

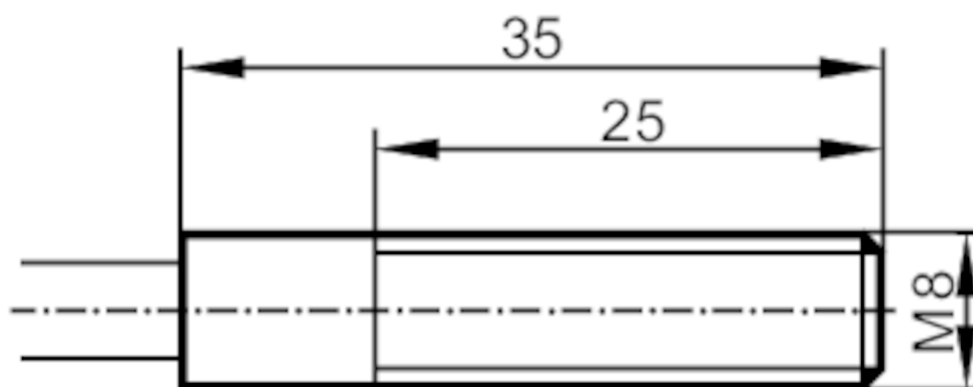

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics

[mm]

70

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

113.6

Version of sensing head

straight

Sensing head thread

M8

Total length

[mm]

600

Min. bending radius

[mm]

30

Fibre arrangement



Fibre material

glass

Fibre head material

stainless steel (303/1.4305)

Fibre sheath material

Vitalon

E20575



Fibre optic diffuse reflection sensor

FT-30-N-V-M8

Accessories	
Items supplied	hexagon nuts: 2 x M8
	tooth lock washers: 2
	knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.