


Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,2M

Article no longer available - archive entry

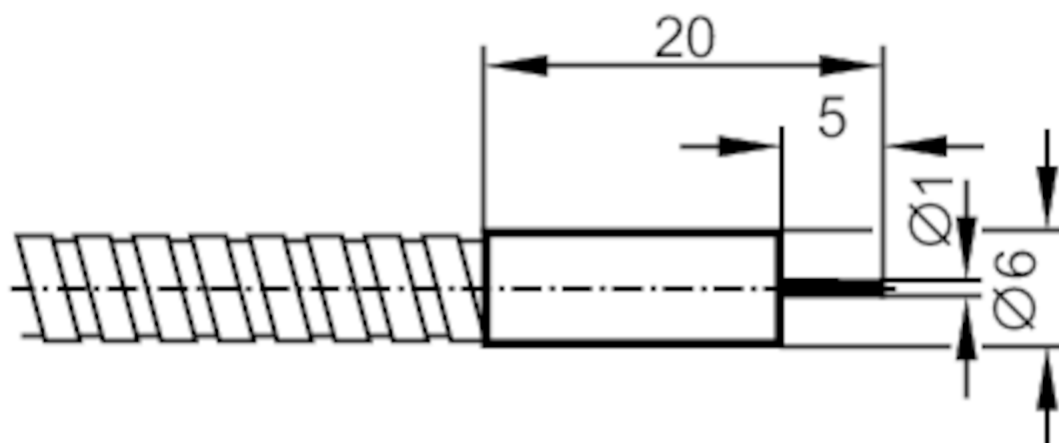

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	8
-------------------------	---

OUF

Range fibre optics [mm]	8
-------------------------	---

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	200; (-5 mm)
Min. bending radius [mm]	20
Materials	Adapter: ABS
Fibre material	glass

E20184



Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,2M

Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.